


Specification



Model Name : AC 0524A

Input Voltage	115 / 230Vac [AUTO SW.]
Input Frequency	47 ~ 63Hz
Max. In-rush Current	Cold start , 30A for 115Vac , 60A for 230Vac
Input Current	3.2A Max for 115Vac 1.6A Max for 230Vac
Output Voltage	29.2Vdc $\pm$ 0.2V (Absorption Charge) 27.4Vdc $\pm$ 0.2V (Float Charge)
Start Point of Floating	0.7A $\pm$ 0.2A
Max. Charging Current	5A
Ripple / Noise	220mVp-p
FAN Control	Fan on fast speed (Bulk / Absorption Charge) Fan on slow speed (Float Charge)
LED Indication	LED1 : RED LED $\rightarrow$ POWER ON LED2 : RED LED $\rightarrow$ CHARGING GREEN LED $\rightarrow$ FULL CHARGE
Dimensions	7.32 inch (186 mm) Length 3.46 inch (88 mm) Width 1.87 inch (47.5 mm) Height
AC Power Cord	NAMA SVT 18AWG X3C

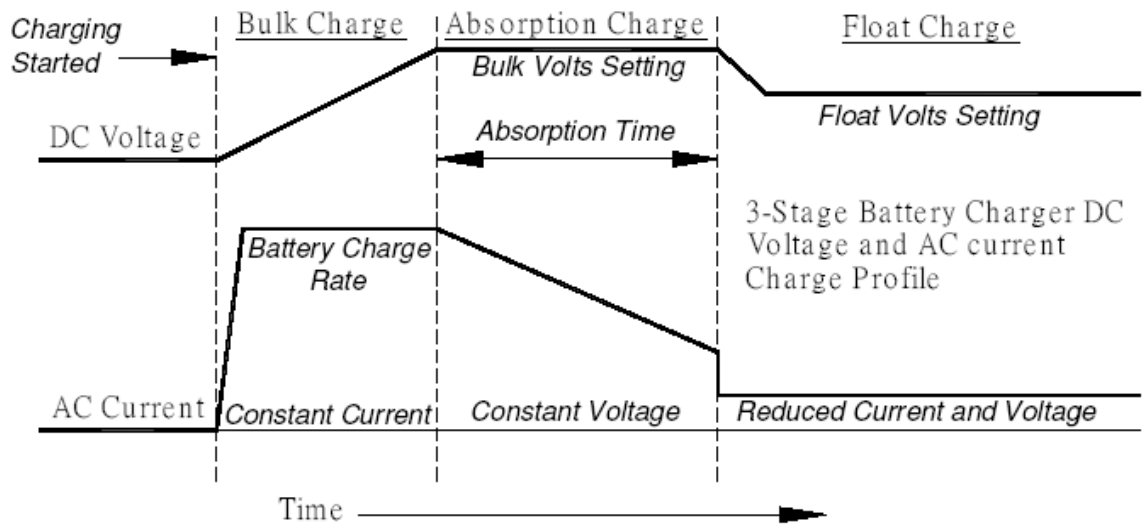

Case Drawing

Body View



Front Panel



Rear Panel

