

AC Centrifugal Blowers Dual Inlet, Ø133mm



ebm-papst Mulfingen


- Dual Inlet fans with an external rotor motor offering the advantage of matched motor and impeller in a compact space saving design.
- Motors: IP44 rated, sealed for life, maintenance free, class B insulation, precision ball bearings and side mounted capacitor and terminal block.
- Impeller: forward curved multi-vane type force fitted for vibration free operation/efficient cooling.
- Body: heavy duty, galvanised steel
- May be mounted in any position

Nominal Data		Curve	Voltage	Frequency	Air Flow	Speed/rpm	Power Input	Current Draw	Noise	Perm. Amb. Temp.	Mass
Part Number	Curve	VAC	HZ	M ³ /h	min ⁻¹	W	A	DB(A)	°C	kg	
D4E133-AA01-57	1	230	50	510	1180	70	0.32	52	40	2.6	
		230	60	540	1240	80	0.35	54	40		

AC Centrifugal Blowers

Dual Inlet, Ø133mm

Performance Curve

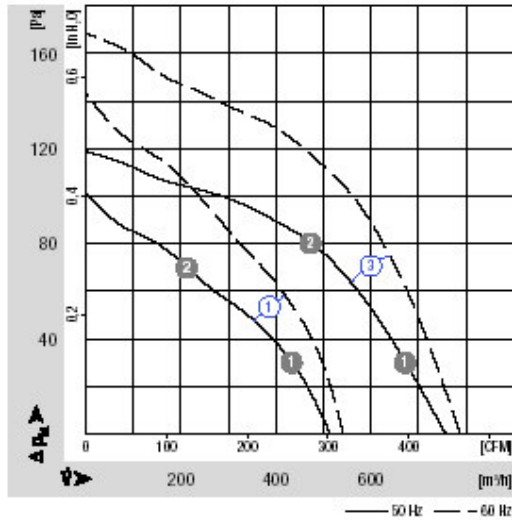

Dimensions

Part Number	A	B	C	D	E	I	J	K	L	M	N	P
D4E133-AA01-57	254	238	108	92	69	215	300	171.5	88	180	76	66

