

**RING**



THE RING PROFESSIONAL RANGE OF INDUSTRIAL AREA FLOODLIGHTS PROVIDE A COMPLETE, COST EFFECTIVE SOLUTION TO ANY OUTDOOR SCHEME WHERE LONG DURATION OR ROUND THE CLOCK FLOODLIGHTING IS REQUIRED E.G. SPORTS FIELDS, CAR PARKS, STORAGE AREAS, MONUMENTS, BUILDING SITES ETC.

MANUFACTURED IN HIGH IMPACT POLYCARBONATE OR ROBUST DIE CAST ALUMINIUM THESE PRODUCTS ARE DESIGNED TO PROVIDE YEARS OF TROUBLE-FREE OPERATION WITH A MINIMUM OF MAINTENANCE

# AREA FLOODLIGHTS



## PROFESSIONAL POLYCARBONATE RANGE

719-456/468/47

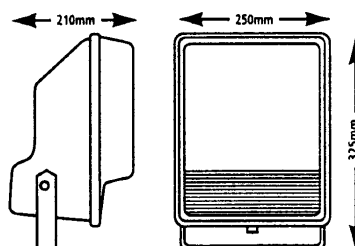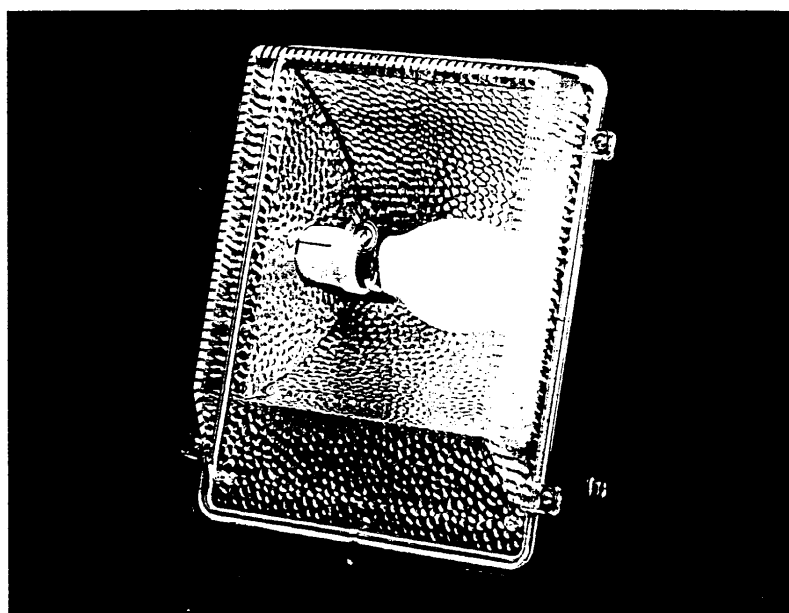

- ✓ REINFORCED VANDAL RESISTANT POLYCARBONATE BODY
- ✓ UV RESISTANT POLYCARBONATE DIFFUSER
- ✓ EPOXY COATED STEEL BRACKET
- ✓ INTEGRAL GONIOMETER (DEVICE FOR MEASURING ANGLES)
- ✓ CE MARKED
- ✓ REFLECTOR OF ANODISED, POLISHED 999 ALUMINIUM
- ✓ ZINC COATED STEEL SCREWS TO PREVENT CORROSION
- ✓ HIGH QUALITY INTEGRAL GEAR
- ✓ SUPPLIED COMPLETE WITH SELF-IGNITED *70W SONE lamp*

## PROFESSIONAL DIE CAST RANGE

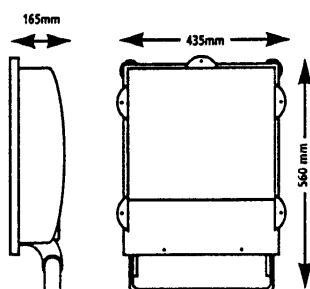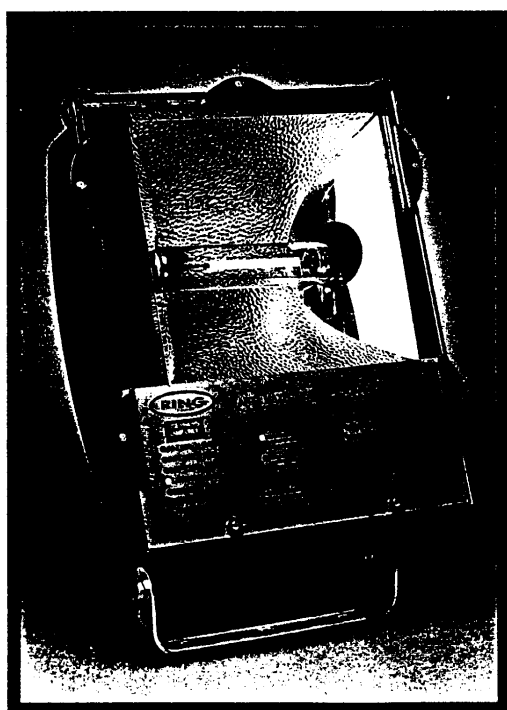

- ✓ IP54 RATED CLASS II PROTECTED LUMINAIRE

719-456 →

CODE	DESCRIPTION	LAMP OPTIONS
HP570C	RING 70W HPS FLOOD C/W LAMP	70W SONE INTEGRAL IGNITOR
HBF80C	RING 80W MBFu FLOOD C/W LAMP	80W MBFu

CODE	DESCRIPTION	LAMP OPTIONS	WATTAGE
HP250RX	RING 250W SON/MH FLOOD EX LAMP	SON-T/MH-T	250W
HP400RX	RING 400W SON/MH FLOOD EX LAMP	SON-T/MH-T	400W

- ✓ DIE CAST IN HIGH QUALITY ALUMINIUM
- ✓ 5MM THICK TOUGHENED GLASS DIFFUSER
- ✓ IP55 RATED
- ✓ SYMMETRIC REFLECTOR IN 999 ANODISED, POLISHED ALUMINIUM
- ✓ HIGH POWER FACTOR INTEGRAL GEAR
- ✓ EPOXY COATED STEEL BRACKET
- ✓ INTEGRAL GONIOMETER (DEVICE FOR MEASURING ANGLES)
- ✓ ZINC COATED STEEL SCREWS TO PREVENT CORROSION
- ✓ CE MARKED
- ✓ E40 LAMPHOLDER