



### ELECTRICAL SPECIFICATION

RATED VOLTAGE	250V AC
RATED CURRENT	6 AMPS @40°C
LINE FREQUENCY	50/60Hz
TEMPERATURE RANGE	-25°C TO 85°C
EARTH LEAKAGE CURRENT	0.47mA
TEST VOLTAGE	2.0KV DC
TERMINATIONS:-	IEC320 APPLIANCE INLET IEC320 APPLIANCE OUTLET

### ELECTRICAL SCHEMATIC

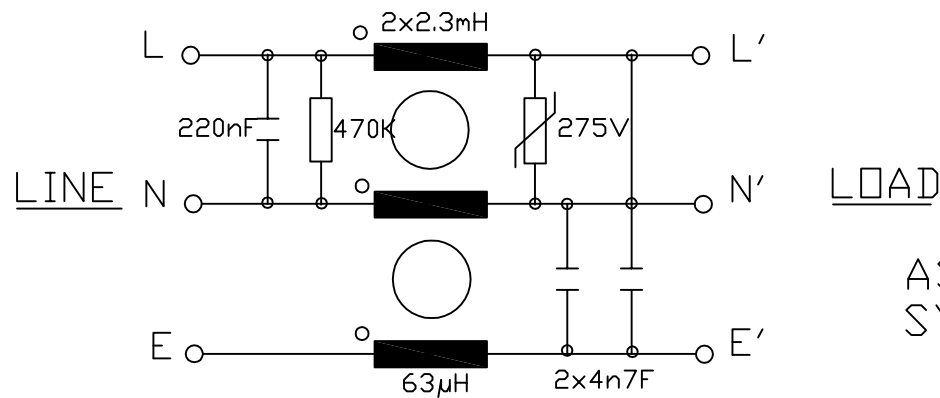

### TYPICAL ATTENUATION (dB)

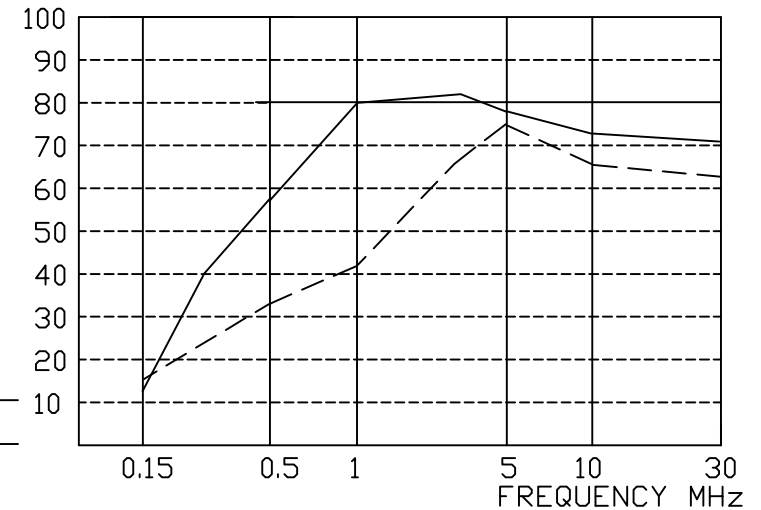

ALL DIMENSIONS IN MM / ANGLES IN DECIMAL DEGREES

DrgNo PMF6-GS

TITLE PMF6 PORTABLE MAINS FILTER

**ROXBURGH EMC**  ISSUE 1

GENERAL SPECIFICATION  
FOR PMF6

CUSTOMER

FILTER REF

Sheet 1 of 1 | Aprvd Date 13/12/01 | Aprvd By SW | Drwn by BS | SCALE NTS | CNN--- | Location N: \DWG\GS\GS000275

©DELTRON EMCON LTD, ROXBURGH HOUSE, FOXHILLS INDUSTRIAL PARK, SCUNTHORPE, NORTH LINCOLNSHIRE, DN15 8QJ TEL +44 1724 281770 F +44 1724 270230