


927-715 to 752 + 317-7257


0603 NYLON CABLE GLAND

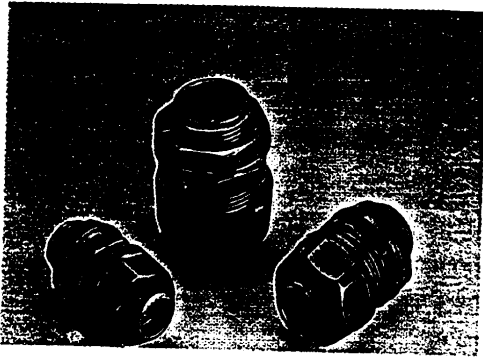

- Material: UL approved nylon 66 94V-2. (Black)
- "CABLE GRAB CLAW" is designed to stay on the gland body to save installation cost and a rubber ring is provided inside the claw to grip cable firmly.
- Good for insulation and protection of cable to go through chassis.


MÉTRIC THREAD

Item No.	Mounting Hole D1	Pitch (mm)	D2	B1	L1	L2	L3	Cable Range	Packing
CG-16	16	1.5	11.0	10.3	14.5	14.0	18.7	5-10	50 PCS
CG-20	20		14.7	14.0	14.5	16.0	18.5	6-13	
CG-25	25		20	19.0	15.0	16.7	21.5	10-18	
CG-32	32		25	24.0	17.8	24.8	24.0	16-22	25 PCS
CG-40	40		32	31.0	17.8	25.8	31.2	20-27	10 PCS
CG-50	50		41.5	40.1	17.8	25.8	32.0	30-38	
CG-63	63		53.2	45.0	17.8	27.1	33.7	35-44	

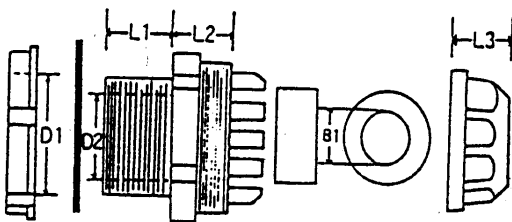

Lock Washer Nut Body Claw Seals Nut

CG-16F	20.8	PF1/2"	11	13.0	9.5	14.0	18.7	5-10	50 PCS
CG-20F	20.8		14.7	14.7	9.5	16.0	18.5	6-13	

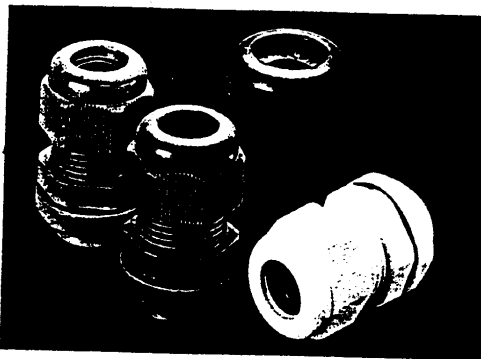

Item No.	Mounting Hole D1	Pitch (mm)	D2	B1	L1	L2	L3	Cable Range	Packing
AG-12	12	1.25						3-6.5	50 PCS
AG-16	16	1.5						5-10	
AG-20	20							10-14	
AG-25	25							13-18	
AG-25S	25							13-18	
AG-32	32							18-25	25 PCS
AG-32S	32							18-25	
AG-40	40							22-32	10 PCS
AG-50	50							30-38	
AG-63	63						34-44		

PG THREAD(DIN STANDARD) WITHOUT WASHER

Item No.	Mounting Hole D1	Pitch (mm)	D2	B1	L1	L2	L3	Cable Range	Packing
EG-7	PG-7 12.1	1.5	8.1	4.9	7.8	4.9	19.0	3.5-6	50 PCS
EG-9	PG-9 14.3		10	7.5	7.5	5.0	21.0	4-8	
EG-11	PG-11 18.23		13.2	9.8	7.5	4.9	24.0	5-10	
EG-13.5	PG-13.5 19.9		15.2	12.6	8.7	4.9	27.0	6-12	
EG-16	PG-16 22.1		17.3	13.7	10.0	5.8	30.0	10-14	
EG-21	PG-21 27.5		22.8	16.5	10.7	5.8	35.8	13-18	25 PCS
EG-29	PG-29 36.2		30.4	24.6	10.5	6.8	45.7	18-25	
EG-36	PG-36							22-32	

