 



Accessories and separate gland parts  
Blank plugs  
with metric thread



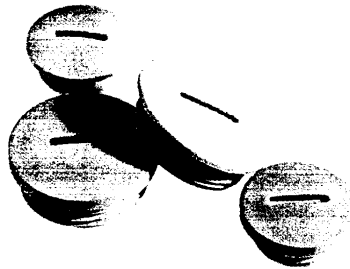

## SKINDICHT® BLK-M / BLK-GL-M Blank plugs

Plastic hole plugs with a male metric thread are for use when existing metric threaded holes are not yet, or no longer required.

 


### Technical Data

 Material:  
BLK-M: Polystyrene  
BLK-GL-M: Polyamide  
reinforced with glass fibre

 Farbe:  
BLK-M/BLK-GL-M:  
RAL 7035 light grey  
RAL 9005 black

 On request:  
Also available with O-ring

 Temperature range:  
BLK-M: -20 °C to +70 °C  
BLK-GL-M: -40 °C to +100 °C

Type Part number	Size M	Thread length mm	Pack size pieces
<b>SKINDICHT® BLK-M</b>			
5200 6600	12 x 1,5	6	100
5200 6610	16 x 1,5	6	100
5200 6620	20 x 1,5	6	100
5200 6630	25 x 1,5	8	100
5200 6640	32 x 1,5	8	50
5200 6650	40 x 1,5	8	25
5200 6660	50 x 1,5	10	25
5200 6670	63 x 1,5	12	25
<b>SKINDICHT® BLK-GL-M light grey</b>			
5200 6100	12 x 1,5	6	100
5200 6110	16 x 1,5	6	100
5200 6120	20 x 1,5	6	100
5200 6130	25 x 1,5	8	100
5200 6140	32 x 1,5	8	50
5200 6150	40 x 1,5	8	25
5200 6160	50 x 1,5	10	25
5200 6170	63 x 1,5	12	25
<b>SKINDICHT® BLK-GL-M black</b>			
5200 6103	12 x 1,5	6	100
5200 6113	16 x 1,5	6	100
5200 6123	20 x 1,5	6	100
5200 6133	25 x 1,5	8	100
5200 6143	32 x 1,5	8	50
5200 6153	40 x 1,5	8	25
5200 6163	50 x 1,5	10	25
5200 6173	63 x 1,5	12	25