


SKINDICHT®

Accessories and separate gland parts
Converters made of brass
with metric connection thread



SKINDICHT® ZS-M Hexagonal converter with metric connecting thread and PG inner thread

A hexagonal converter with
metric outer threads and PG
inner threads.

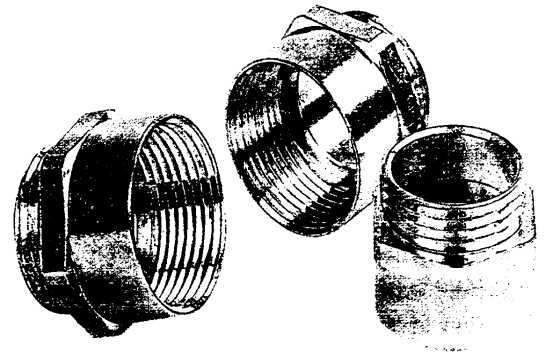

SKINDICHT® ZS-M-XL With long metric connecting thread

Material: Nickel-plated brass



Type Part number	Outside thread M	Inside thread PG	Wrench size mm	Thread length mm	Pack size pieces
SKINDICHT® ZS-M					
5210 4330	12 x 1,5	7	14	5	100
5210 4340	16 x 1,5	9	18	5	100
5210 4360	20 x 1,5	11	22	6	100
5210 4370	20 x 1,5	13,5	22	6	100
5210 4380	20 x 1,5	16	24	6	50
5210 4400	25 x 1,5	21	30	7	50
5210 4410	32 x 1,5	29	40	8	25
5210 4420	40 x 1,5	36	50	8	10
5210 4430	50 x 1,5	42	57	9	10
5210 4440	63 x 1,5	48	66	10	10

Skindicht® ZS-M-XL					
5210 4335	12 x 1,5	7	14	10	100
5210 4345	16 x 1,5	9	18	10	100
5210 4365	20 x 1,5	11	22	10	100
5210 4375	20 x 1,5	13,5	22	10	100
5210 4385	20 x 1,5	16	24	10	50
5210 4405	25 x 1,5	21	30	11	50
5210 4415	32 x 1,5	29	40	13	25
5210 4425	40 x 1,5	36	50	13	10
					10