

SKINTOP® DIX-M


Multiple sealing insert for SKINTOP® cable glands in metric style





SKINTOP® DIX-M Multiple sealing insert


Another constituent of the SKINTOP® range is the multiple sealing insert DIX-M which makes the SKINTOP® gland a multiple gland. Instead of normal or reduction sealing inserts, a sealing with several drill holes is used. SKINTOP® DIX-M sealing rings allow several cables

 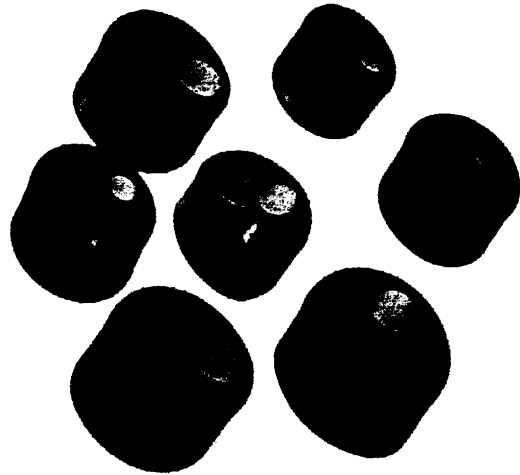
to be lead through one gland simultaneously. Since this way, it becomes unnecessary to use a gland for each cable, it is possible to reduce the size of parts. SKINTOP® DIX-M allows a more compact line of cables in one direction.

 




Technical Data

-  Material: NBR
-  Protection class: IP 54

 Note:
Special shapes on request

 Temperature range:
-30 °C to +100 °C
static: -40 °C to +100 °C

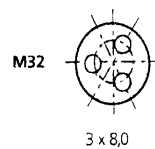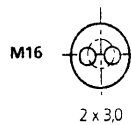

Part number	Thread size M	Number of cables x cable diameter	Type	Pack size pieces
SKINTOP® DIX-M				
5331 6230	M 16	2 x 3	16230	100
5331 6240	M 16	2 x 4	16240	100
5332 0250	M 20	2 x 5	20250	100
5332 0340	M 20	3 x 4	20340	100
5332 5260	M 25	2 x 6	25260	50
5332 5360	M 25	3 x 6	25360	50
5332 5370	M 25	3 x 7	25370	50
5332 5450	M 25	4 x 5	25450	50
5332 5540	M 25	5 x 4	25540	50
5333 2280	M 32	2 x 8	32280	50
5333 2380	M 32	3 x 8	32380	50
5333 2460	M 32	4 x 6	32460	50
5333 2470	M 32	4 x 7	32470	50
5334 0969	M 40	9 x 6,9	40969	25