


## TDB MINIATURE ELETROMAGNETIC BUZZERS


### DIMENSIONS

masking label

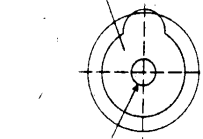


Ø2.6  
sound emission hole

**Top View**

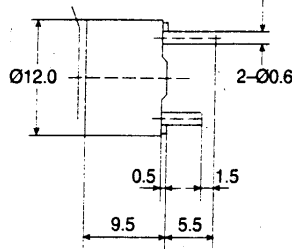

**Side View**

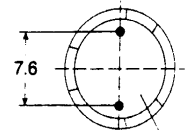

potting

**Bottom View**

All dimensions are in mm

THIS MINIATURE BUZZER IS FULLY SEALED TO WITHSTAND WAVE SOLDER AND CLEANING PROCESSES.

### SPECIFICATION

	TDB01	TDB03	TDB05	TDB12
RATED VOLTAGE	1.5V DC	3V DC	5V DC	12V DC
OPERATING VOLTAGE	1.25-2V DC	2.5-4V DC	4-6.5 V DC	8-16 V DC
RESONANT FREQUENCY	2300Hz	2300Hz	2300Hz	2300Hz
SOUND PRESSURE LEVEL @ 10cm	75dB	80dB	85dB	85dB
MAX CURRENT CONSUMPTION	30mA	30mA	30mA	30mA
OPERATING TEMPERATURE °C	-10to+60	-40to+85	-40to+85	-40to+85