

Industrial Style Thermocouples


These Industrial Style Sensors use a Type 'J' or 'K' Mineral Insulated Thermocouple. Housed in a 310 Stainless Steel closed end sheath.

Terminated in an Aluminium IP67 connection and has a fitted terminal block for easy connection.


Available Lengths : 150, 250 & 500mm

Diameter : 6mm

- Industrial Style Thermocouple
- Type 'J' or 'K' - Insulated Hot Junction
- IP67 Terminal Head
- 310SS Sheath
- Operating Temperature Range -100°C to +1100°C

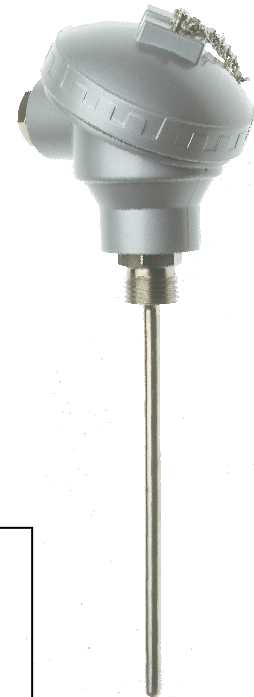

Global Part No.	Description
91-9320-03	Type 'J' KNE 6mm x 150mm
91-9321-03	Type 'J' KNE 6mm x 250mm
91-9322-03	Type 'J' KNE 6mm x 500mm
91-9323-03	Type 'K' KNE 6mm x 150mm
91-9324-03	Type 'K' KNE 6mm x 250mm
91-9325-03	Type 'K' KNE 6mm x 500mm

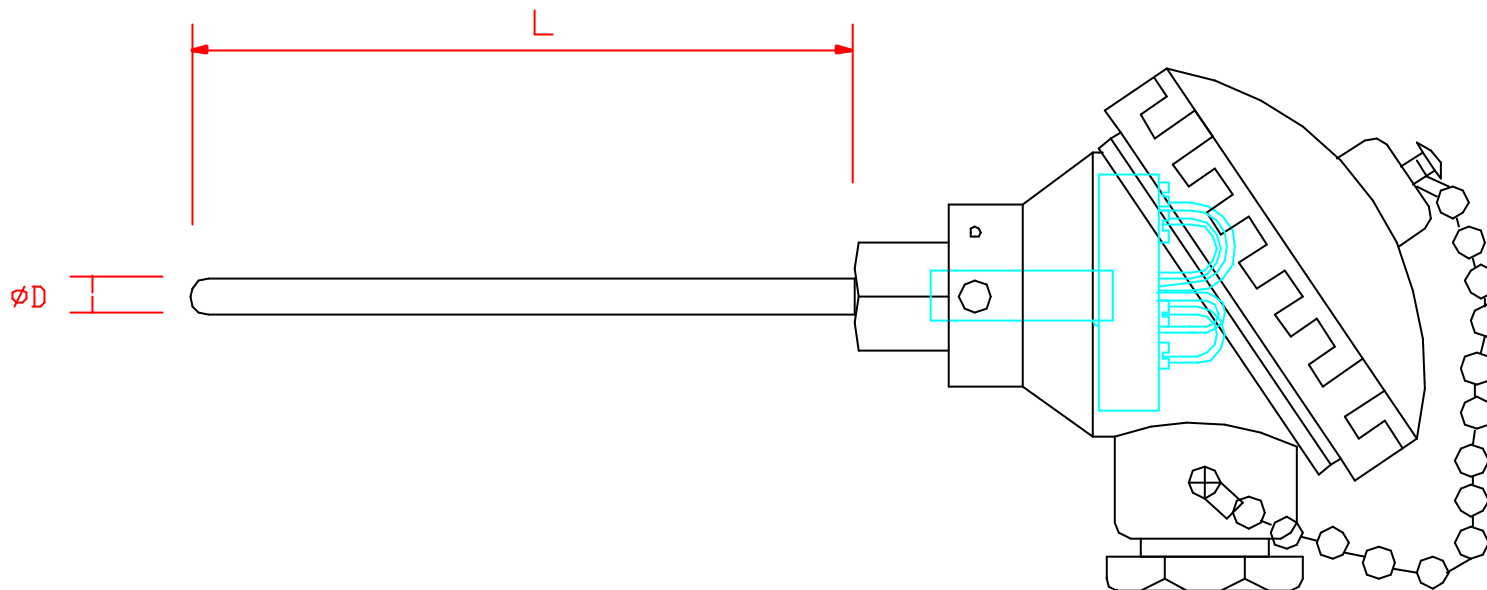

Item	Global Part No.	T/C	D	L	Date
A	91-9320-03	J	6	150	10.01.05
B	91-9321-03	J	6	250	10.01.05
C	91-9322-03	J	6	500	10.01.05
D	91-9323-03	K	6	150	10.01.05
E	91-9324-03	K	6	250	10.01.05
F	91-9325-03	K	6	500	10.01.05

ISSUE	MODIFICATION	DRAWN	APP	DATE	SHEET 1 OF 1 SHEETS.	THIS DRAWING REMAINS THE PROPERTY OF GLOBAL LIMITED AND MAY NOT BE REPRODUCED WITHOUT OUR PERMISSION.		DATE	GLOBAL MEASUREMENT AND CONTROL LTD.
						TOLERANCE	TITLE		
1	For Reference Only	S.A.	S.A.	10/01/05	MATERIAL	X ± 0.50	Industrial Thermocouple	S.A.	10.01.05
2						X.X ± 0.25			
3					FINISH	X.XX ± 0.10	PART NUMBER	91-9320-03 to 91-9325-03	DRAWING NUMBER
4					CLEAN & BURR FREE	SCALE	N.T.S.	LIST PART NO	XX-XXXX-XX

UNIT 17, FORD LANE BUSINESS PARK
 FORD LANE, NR ARUNDEL
 WEST SUSSEX BN18 0JZ
 TELEPHONE: 01243 555277
 FAX: 01243 555177