 



DESCRIPTION	NYLON 6/6 CABLE TIES NATURAL & BLACK AS SUPPLIED TO, FARNELL	QUALITY SYSTEM NO: D A V 1 2 7 9
DISTRIBUTION	MANAGING DIRECTOR	SHEET 1 of 1
SALES DIRECTOR.	INSPECTION REPRESENTATIVE	ISSUE DATE 15-3-93
TEST. STORES		SIGNED. 

Material Nylon 6/6 ( Flammability to U L 9 4 V 2 )  
 Manufacturing Spec To M I L 2 0 6 9 3 B  
 Testing Spec M I L 2 3 1 9 0 E

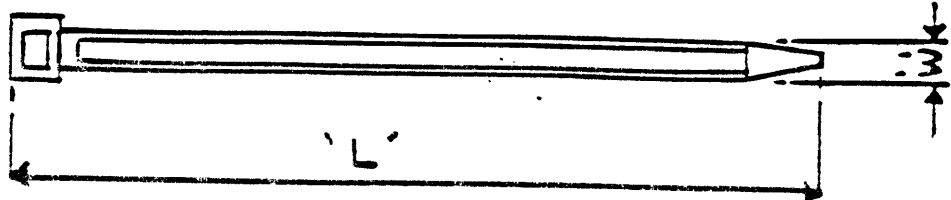

Working Temperature - 40°C to + 85°C

DAVID PART No; NATURAL	DAVID PART No; BLACK	FARNELL PART No;	'L' mm	'W' mm	CABLE Braid DIA mm	TENSILE STRENGTH NCS
NT 20M	-	268.495	102	2.5	20	8.1
NT 50M	-	268.501	200	2.5	50	8.1
NT 30I	-	268.513	140	3.6	30	18.2
NT 75I	-	268.525	200	3.6	75	18.2
NT 24S	-	268.537	120	4.8	24	22.2
NT 50S	-	268.549	200	4.8	50	22.2
NT 75S	-	268.550	250	4.8	75	22.2
NT 100S	-	268.562	370	4.8	100	22.2
NT 50 LH	-	268.574	200	7.6	50	54.5
NT 105 LH	-	268.586	370	7.6	105	54.5
-	NTB 20M	268.598	102	2.5	20	8.1
-	NTB 50M	268.604	200	2.5	50	8.1
-	NTB 30I	268.616	140	3.6	30	18.2
-	NTB 75I	268.628	200	3.6	75	18.2
-	NTB 24S	268.630	120	4.8	24	22.2
-	NTB 50S	268.641	200	4.8	50	22.2
-	NTB 75S	268.653	250	4.8	75	22.2
-	NTB 100 S	268.665	370	4.8	100	22.2
-	NTB 50 LH	268.677	200	7.6	50	54.5
-	NTB 105LH	268.689	370	7.6	105	54.5

# DAVICO

Keeping electricity firmly in its place

Davico Industrial Limited, Charles Street, West Bromwich,  
 West Midlands B70 0A2 U.K. Tel: 021-520 7101.  
 Telex: 338846 DAVICO G

REV 1	DATE	SIG
REV 2	DATE	SIG
REV 3	DATE	SIG