


19" complete chassis from aluminium, plain top cover and base plate

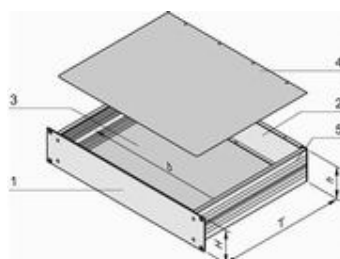

h = clear height (overall) (H - 8.1 mm)
b = clear installation width = 403 mm

Part no.: 20860-602

Features:

- Complete chassis from aluminium
- Detachable rear panel for easy machining
- EMC shielding of approx. 30 dB(A) at 1 GHz (without additional shielding material)
- In accordance with standard IEC 60297-3-100, -101, -105
- 19" and ATX power supplies can be assembled in the 1 U case height up to a clearance of 35 mm

Add to basket




NEW PRODUCT

RoHS COMPLIANT

Technical information:

| Description | Height | Height H | Depth T |
|--------------------------------|--------|----------|---------|
| Solid top cover and base plate | 1 U | 43.7 mm | 280 mm |

Downloads:

3D PDF (STEP/PDF) ([Log in](#) Required) 
User manual ([Log in](#) Required)
EMC / HF test report ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).
If you do not yet have a user name, you may [Register here](#).

Delivery comprises: Kit

| Item | Qty | Description |
|------|-----|-------------------------------------------------------------------------|
| 1 | 1 | Front panel, Al extrusion, 3 mm; front anodised, rear etched |
| 2 | 1 | Rear panel, Al, 2 mm, etched |
| 3 | 1 | Base plate, plain, Al, 1 mm |
| 4 | 1 | Cover plate, plain, Al, 1 mm |
| 5 | 2 | Side panel, Al extrusion, raw; with grooves for threaded insert (2 × 7) |
| 6 | 1 | Assembly kit |

Accessories:

| Part no. | Description | |
|---------------------------|-------------------|---------------|
| 20860-130 | EMC gasketing kit | Add to basket |

| | | |
|------------------|---------------------------------------------------------------------------------------------------------------------------------|----------------------|
| | Silicone/nickel gasket 2100 mm for contacting side panel/cover plate; Seal, stainless steel, for front panel/cover plate, 1 kit | |
| 20860-256 | Front handles incl. assembly kit for 1 U, Al extrusion, anodised, PU 2 pieces | Add to basket |