

## 19" complete chassis from aluminium, perforated top cover and base plate




Part no.: 20860-621

## Features:

- Complete chassis from aluminium
- Detachable rear panel for easy machining
- EMC shielding of approx. 30 dB(A) at 1 GHz (without additional shielding material)
- In accordance with standard IEC 60297-3-100, -101, -105
- 19" and ATX power supplies can be assembled in the 1 U case height up to a clearance of 35 mm

Add to basket

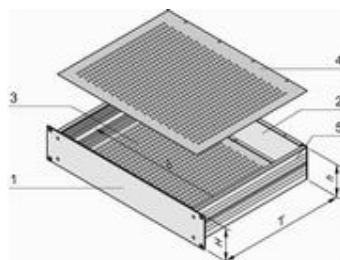

h = clear height (overall) (H - 8.1)  
b = clear installation width = 403 mm


NEW PRODUCT

RoHS COMPLIANT

## Technical information:

Description	Height	Height H	Depth T
Perforated top cover and base plate	1 U	43.7 mm	220 mm

## Downloads:

3D PDF (STEP/DWG/DXF/PDF) ([Log in](#) Required)   
 User manual ([Log in](#) Required)  
 EMC / HF test report ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).  
 If you do not yet have a user name, you may [Register here](#).

## Delivery comprises: kit

Item	Qty	Description
1	1	Front panel, Al extrusion, 3 mm; front anodised, rear etched
2	1	Rear panel, Al, 2 mm, etched
3	1	Base plate, perforated, Al, 1 mm
4	1	Cover plate, perforated, Al, 1 mm
5	2	Side panel, Al extrusion, raw; with grooves for threaded insert (2 × 7)
6	1	Assembly kit

## Accessories:

Part no.	Description	
<a href="#">20860-130</a>	EMC gasketing kit	Add to basket

	Silicone/nickel gasket 2100 mm for contacting side panel/cover plate; Seal, stainless steel, for front panel/cover plate, 1 kit	
<b>20860-256</b>	Front handles incl. assembly kit for 1 U, Al extrusion, anodised, PU 2 pieces	<b>Add to basket</b>