

## 19" complete chassis from aluminium, perforated top cover and base plate



Photo shows 1 U

Part no.: 20860-627

## Features:

- Complete chassis from aluminium
- Detachable rear panel for easy machining
- 19" and ATX power supplies can be assembled in the 1 U case height up to a clearance of 35 mm
- EMC shielding of approx. 30 dB(A) at 1 GHz (without additional shielding material)
- In accordance with standard IEC 60297-3-100, -101, -105

Add to basket




NEW PRODUCT

RoHS COMPLIANT

## Technical information:

Description	Height	Height H	Depth T
Perforated top cover and base plate	3 U	132.6 mm	280 mm

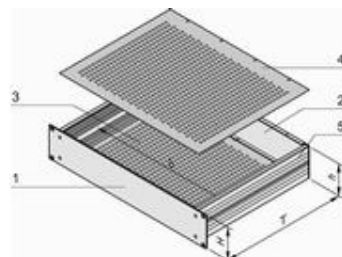

h = clear height (overall) (H - 8.1)  
 b = clear installation width = 403 mm

## Downloads:

User manual ([Log in](#) Required)  
 EMC / HF test report ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).  
 If you do not yet have a user name, you may [Register here](#).

## Delivery comprises: kit

Item	Qty	Description
1	1	Front panel, Al extrusion, 3 mm; front and rear side of front panels clear passivated
2	1	Rear panel, Al, 2 mm, etched
3	1	Base plate, perforated, Al, 1 mm
4	1	Cover plate, perforated, Al, 1 mm
5	2	Side panel, Al extrusion, raw; with grooves for threaded insert (2 × 7)
6	1	Assembly kit

## Accessories:

Part no.	Description	
<a href="#">20860-130</a>	EMC gasketing kit Silicone/nickel gasket 2100 mm for contacting side panel/cover plate; Seal, stainless steel, for front panel/cover plate, 1 kit	Add to basket

**20860-258**

Front handles  
incl. assembly kit for 3 U, Al extrusion, anodised, PU  
2 pieces

**Add to basket**