


19" complete chassis from aluminium, perforated top cover and base plate



Photo shows 1 U

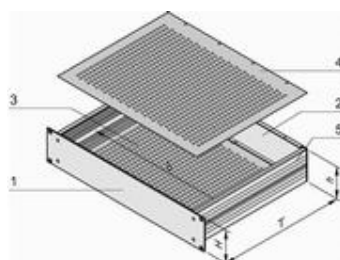

h = clear height (overall) (H - 8.1)
b = clear installation width = 403 mm

Part no.: 20860-633

Features:

- Complete chassis from aluminium
- Detachable rear panel for easy machining
- 19" and ATX power supplies can be assembled in the 1 U case height up to a clearance of 35 mm
- EMC shielding of approx. 30 dB(A) at 1 GHz (without additional shielding material)
- In accordance with standard IEC 60297-3-100, -101, -105

Add to basket



NEW PRODUCT

RoHS COMPLIANT

Technical information:

Description	Height	Height H	Depth T
Perforated top cover and base plate	4 U	177 mm	400 mm

Downloads:

User manual ([Log in](#) Required)
EMC / HF test report ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).
If you do not yet have a user name, you may [Register here](#).

Delivery comprises: kit

Item	Qty	Description
1	1	Front panel, Al extrusion, 3 mm; front and rear side of front panels clear passivated
2	1	Rear panel, Al, 2 mm, etched
3	1	Base plate, perforated, Al, 1 mm
4	1	Cover plate, perforated, Al, 1 mm
5	2	Side panel, Al extrusion, raw; with grooves for threaded insert (2 × 7)
6	1	Assembly kit

Accessories:

Part no.	Description	
20860-259	Front handles incl. assembly kit for 4 U, Al extrusion, anodised, PU 2 pieces	Add to basket

20860-130

EMC gasketing kit
Silicone/nickel gasket 2100 mm for contacting side
panel/cover plate; Seal, stainless steel, for front
panel/cover plate, 1 kit

Add to basket