

$\square$  1/2"

## "Standard" ratchets

## Facom "round head" ratchets

 S.171  
●●○○○○



 S.161  
●●○○○○




 S.151  
○○○○○○



 S.154  
○○●○○○



 S.143A  
●●○○○○●

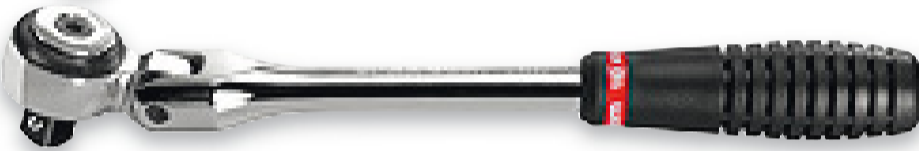

 S.153A  
●●○○○○●



## Metal grip ratchets

 S.155A  
●●○○○○




 S.157A  
●●○○○○



 S.158A  
●●○○○○



 S.156  
Ratchet attachment.  
Female drive :  $\square$  1/2"..  
Male drive :  $\square$  1/2".



## "Parking meter" ratchets

 SM.171  
●●○○○○



 SM.161  
●●○○○○



 SM.150  
●●○○○○



## The solution for congested spaces

## Compact :

- The Facom ratchet mechanism ensures a very compact round head.

## Precise :

- 72-tooth mechanism gives increments of only 5°.

## High performance :

- Meet the requirements of ISO 3315, DIN 3122 NF ISO 3315.

- Ideal for environments where PVC grips are vulnerable to solvent attack.

## Sturdy :

- "Parking meter" ratchets are ideal for use in difficult working conditions : their mechanism is protected and has fewer teeth (50) than a "round-head" ratchet (72).

## Ergonomic :

- Recessed reverse lever avoids accidental reversal and is easier to operate with gloved hands.