

# Standard 1/2" range

## SX.LA 1/2" drive long-reach Torx® bit sockets

- Non-removable bits.

	Torx® no.	I*	D mm	I mm	L mm	ΔΔ g
<b>SX.40LA</b>	T40	6,60	22,8	84	120	95
<b>SX.45LA</b>	T45	7,77	22,8	84	120	95
<b>SX.55LA</b>	T55	11,17	22,8	104	140	220
<b>SX.70LA</b>	T70	15,49	23,1	104	140	280



## Set of 1/2" drive Torx® bit sockets

### AMEX.3


- Comprising : SXM.20, SXM.25, SXM.27, SXM.30, SXM.40, SXM.45, SXM.50, SXM.55, SXM.60.
  - Plastic case BP.102 : 204 x 122 x 52 mm.
  - Tray PL.455.
- ΔΔ : 865 g.



## SV.B 1/2" drive XZN® spline bit sockets

- Non-removable bits.

	Ø Screw	D mm	I mm	L mm	ΔΔ g
<b>SV.6B</b>	M6	22,8	24	60	60
<b>SV.8B</b>	M8	22,8	24	60	60
<b>SV.10B</b>	M10	22,8	24	60	70
<b>SV.12B</b>	M12	22,8	24	60	80
<b>SV.14B</b>	M14	22,8	24	60	100
<b>SV.16B</b>	M16	23,1	24	60	110

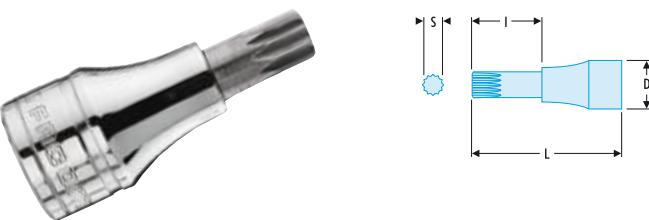

## SV.LB 1/2" drive long-reach XZN® spline bit sockets

- Non-removable bits.

	Ø Screw	D mm	I mm	L mm	ΔΔ g
<b>SV.6LB</b>	M6	22,8	64	100	80
<b>SV.8LB</b>	M8	22,8	64	100	80
<b>SV.10LB</b>	M10	22,8	64	100	90
<b>SV.10ELB</b>	M10	22,8	120	120	110
<b>SV.12LB</b>	M12	22,8	64	100	120
<b>SV.12ELB</b>	M12	22,8	104	140	150
<b>SV.14LB</b>	M14	22,8	64	100	150



## Special 1/2" sockets for automotive applications

For details of our 1/2" special automotive sockets,  
see section 18.

- Spark plug sockets
- Cylinder head sockets
- Injector sockets



## Rack sets of 1/2" drive bit sockets

ST : for hexagon socket heads.

SX : for Torx® heads.

SV : for XZN® spline heads.

	Sizes	Rack	ΔΔ g
<b>ST.40</b>	STM 6-8-10-12-14-17-19	CKS.97	830
<b>ST.41</b>	SHPLA 6-7-8-10-12	CKS.90	610
<b>SX.41</b>	SXM 20-25-27-30-40-45-50-55	CKS.95	640
<b>SV.40A</b>	SVA 6-8-10-12	CKS.90	340
<b>SV.41A</b>	SVLB 8-10-12	CKS.90	440

