
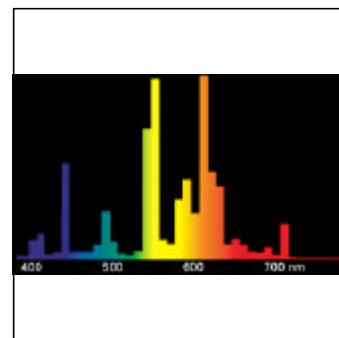
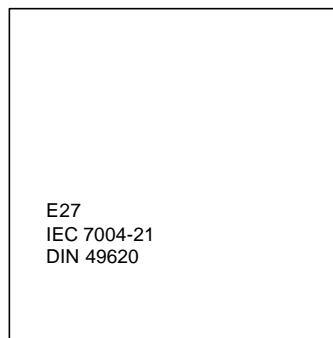


Compact fluorescent lamps with integrated control gear
OSRAM DULUX® EL Longlife E27
DULUX EL LL 7 W/41-827 E 27

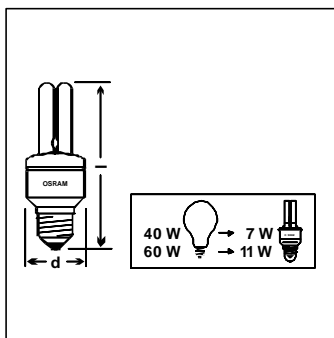

Reference :	DULUX EL LL 7 W/41-827 E 27	Rated wattage [W] :	7
Supply voltage [V/Hz] :	220-240/50-60	Current Effective value [mA] :	70
Light colour :	LUMILUX INTERNA®	Colour rendering group [-] :	1 B
Luminous flux [lm] :	400	Diameter d [mm] :	45
Length l [mm] :	129±3	Weight [g] :	70
Base :	E27	Standard pack [pcs] :	10
EAN 40 50300 :	288819	ILCOS :	FBT-7/27/1B-220/240-E27

OSRAM DULUX® EL LONGLIFE lamps are super-compact premium-quality fluorescent lamps with electronic control gear and E27 bases.

- 12 year life (at around 3h/day)
- High luminous efficacy - up to 80% energy savings
- E27 base for direct replacement of GLS lamps
- Excellent colour rendering, excellent light distribution
- Universal burning position
- Low weight
- Flicker-free starting and flicker-free operation
- Reliable starting down to -30°C (5W down to -20°C)
- More light without temperature problems in GLS lamp luminaires
- 5W to 11W suitable for emergency lighting on 230V dc
- OSRAM DULUX® EL 15W and 20W are available in 120V versions (some of the technical data is different)

Commercial applications: restaurants, hotels, foyers, ticket offices, corridors, doctors' surgeries and offices. Major advantage: much longer relamping intervals.

Domestic applications: All rooms, especially where continuous economical lighting is needed or where the lamps have to withstand frequent switching.