

1216251


(4178)

(de00576)



FENWAL ELECTRONICS

192 SERIES UNI-CURVE[®] R-T MATCHED INTERCHANGEABLE NTC THERMISTORS

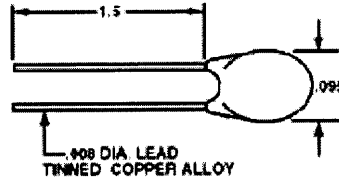

Eliminate need for individual R-T calibration. Operating temperature: 0°C to 70°C. Tolerance: **type 192-xxxxxT**, $\pm 0.2^\circ\text{C}$; **type 192-xxxxxV**, $\pm 0.5^\circ\text{C}$; **type 192-xxxxxW**, $\pm 1.0^\circ\text{C}$. DC power: 0.75mW/°C. Time constant: 15 sec. Radial lead package. Diameter: 0.095". Lead length: 1.50". Meet MIL-T-23648.

Stock No.	Type	Ohms @ 25°C	Resistance Ratio
96F6242	192-501DEV-A01	500	6.35
46F3214	192-102DET-A01	1k	6.35
96F6243	192-102DEW-A01	1k	6.35
30F1796	192-222LET-A01	2,252	9.10
30F1797	192-302LET-A01	3k	9.10
30F1798	192-502LET-A01	5k	9.10
30F1799	192-103LET-A01	10k	9.10
83F7216	192-103LEV-A01	10k	9.10
96F6247	192-103LEW-A01	10k	9.10

30F1800	192-303KET-A01	30k	8.72
46F3215	192-503QET-A01	50k	8.72
30F1802	192-104QET-A01	100k	8.72
96F6252	192-104QEV-A01	100k	10.45