


**For price information, refer to the enclosed pricelist**

# Locks & Accessories

## Brass I.D. Tags

Provides instant identification of assigned padlock user. Designed to withstand rugged work environments. Tags can be personalised using commercial engravers or stamp kits. Will fit up to 9.5 mm diameter shackles.

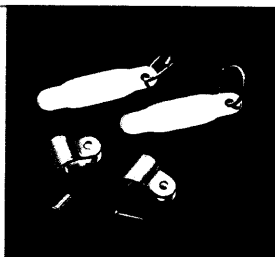

**Available per pack of 12**

Part No.	Description
265378	12 Brass Tags & Attachment Rings
265379	12 Collars and Rivets

## Padlock Eyes

Some equipment needs modification to accept locks and Lockout devices. These padlock eyes can help you to do this.

Available in two versions:

- Surface mounted eyes made of hard wrought steel
- Tamper resistant inside mounting eyes.
- 38 mm wide, accepts shackle diameter up to 16 mm.



Part No.	Description	Package
065686	Surface Mount	6 pairs
065687	Inside Mount	2

## Safety Lockouts

These Lockouts allow up to six workers to lockout a single energy source. They are made of vinyl coated high tensile steel and are plated to resist rust. They accept six padlocks up to 9.5 mm shackle diameter.

Standard package: 12 pieces

**Available in 2 sizes**


Part No.	Shackle ring diameter
265375	25 mm
265376	38 mm



## Lockout Starter Kit

- 2 x 25 mm Safety Lockouts
- 6 x 19 mm Steel Padlocks (one of each colour)
- 6 Brass I.D. tags,
- 6 Collar Attachments

**Part No.: 265380**

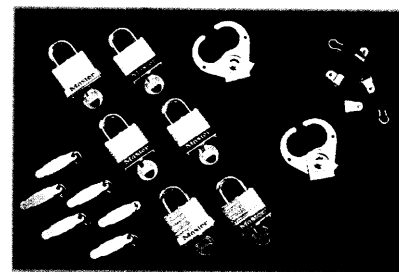

## Economy Lockout

Used on fuse or switch boxes, the sturdy steel lockouts have a 25.4 mm hasp and 15.87 mm holes for up to six padlocks


**Part No.: 236920**



## Stubby Lockout

Versatile and durable, use these when lockout conditions vary in size. Our stubby lockouts allow you to go from locking out small switch boxes to large control units and levers without having to carry and search for different sized hasps. Uniquely constructed with two hasp sizes, one measuring 31.75 mm x 44.45 mm, the other 19.05 mm round, they are made of heavy duty steel and hold up to six locks at one time.


**Part No.: 236919**

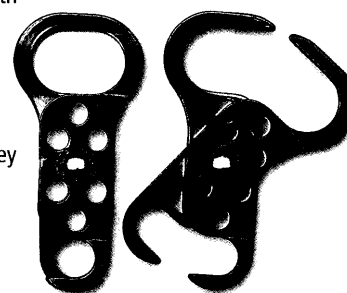

## Heavy Duty Steel Lockout

Tamperproof design prevents vandalism. The solid U-shape steel bolt cannot be pried apart once the locks are in place. The lockout holds up to 3 locks, inside diameter of the U-shape bolt measures 25.4 mm.

**Part No.: 236918**

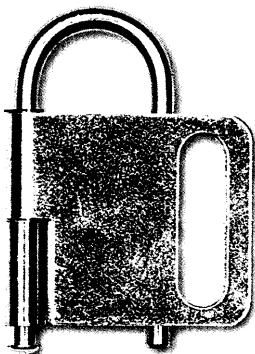

## Aluminium Lockout

The unique design of this one-piece lockout prevents someone from opening the hasp. The U-bolt is attached with a metal pin which allows it to open but when locks are in place remains closed. Constructed of aluminium and has a red plastic coating which allows greater visibility and protection. Holes measure 9.52 mm and will fit any of Brady's locks. Inner hasp measures 25.4 mm

**Part No.: 236917**

