
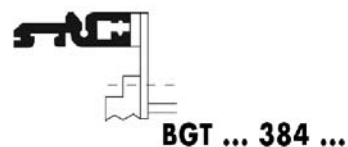


19" subracks

3 U subracks

basic unit: 1 = 2 x side panels; **2** = 2 x front module rail; **3** = 2 x rear module rail; **4** = 2 x fixing angles (only BGTO and BGTG); mounting material

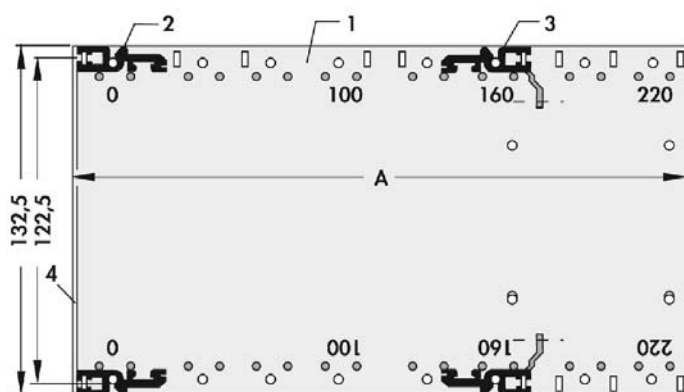

art. no.	19" fixing part	dim. [mm]
		A
BGT 384 180 ...	angled side panel	175.5
BGT 384 240 ...	angled side panel	235.5
BGT 384 300 ...	angled side panel	295.5
BGTG 384 180 ...	fixing angle with handle perforation	175.5
BGTG 384 240 ...	fixing angle with handle perforation	235.5
BGTG 384 300 ...	fixing angle with handle perforation	295.5
BGTO 384 180 ...	fixing angle without handle perforation	175.5
BGTO 384 240 ...	fixing angle without handle perforation	235.5
BGTO 384 300 ...	fixing angle without handle perforation	295.5
please indicate:	... rear module rail (optional) IZ=integrated Z-rail	

3 U insert module designs
Guide rail
Part front panels
Reinforced guide rails

→ N 49
→ N 31
→ N 58 - 64
→ N 32

Insert modules
Insert modules 6 U
Handles for part front panels
Extractor for part front panels

→ N 41 - 45
→ N 46 - 48
→ N 67
→ N 66

N 22

A

B

C

D

E

F

G

H

I

K

L

M

N