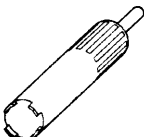
 


RMQ 16

Accessories

	Life	Colour	Type	Price	Std. pack
	t_{mean} (AC)		Article no.	See Price List	
Filament bulbs W 2×4.6 d					
	1.0 W/6 V	10,000 h	WBGL 6 090223		50 off
	1.0 W/12 V	15,000 h	WBGL 12 089968		50 off
	1.0 W/24 V	7,000 h	WBGL 24 089247		100 off
Multiple LEDs W 2×4.6 d					
For DC and AC voltage					
	0.25 W/6 V	60,000 h	WBLED-GE 6 055711		10 off
		●	WBLED-GN 6 055712		
		●	WBLED-RT 6 055713		
	0.25 W/12 V	60,000 h	WBLED-GE 12 055714		
		●	WBLED-GN 12 055715		
		●	WBLED-RT 12 055716		
	0.25 W/24 V	60,000 h	WBLED-GE 24 089226		
		●	WBLED-GN 24 090196		
		●	WBLED-RT 24 089189		
Combination box spanner					
	For lock nuts, with bulb extractor		R16-MS 090297		10 off
Insulated sleeve					
	for 2.8 × 0.8 mm fast-on connectors, can be connected from the front		ISH 2.8 090267		100 off
Fast-on connectors					
	2.8 × 0.8 mm for 0.5–1 mm ² conductor cross-sections		LT 306.022.3 058863		100 off
Blanking plugs IP 65					
	For blanking off reserved locations, grid spacing 18 × 18 mm	●	Q188S 037985		10 off
	For blanking off reserved locations, grid spacing 25 × 25 mm	●	Q258S 036976		10 off
Anti-rotation feature					
	Guard ring as an anti-rotation feature for all RMQ 16 actuators		VS 046301		50 off

√Prefabricated plug-in cables → page 01/009