




FARNELL GROMMET KIT

**Farnell  
Technical  
Data  
Service**

Order Code 151-201

**OPEN  
GROMMETS**

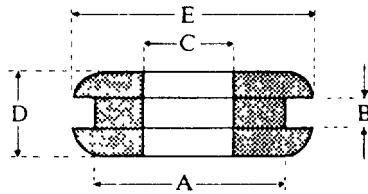

A	B	C	D	E	
4.8	1.6	3.2	6.4	8.0	PV2
6.4	1.6	4.8	7.1	9.5	PV6
6.4	1.6	4.0	6.4	9.5	PV5
8.0	1.6	4.8	6.4	11.1	PV24
9.5	1.6	4.8	5.6	12.7	PV35
9.5	1.6	6.4	6.4	14.3	PV36
9.5	1.6	7.5	6.4	13.5	PV45
9.5	1.6	8.0	4.8	14.3	PV37A
9.5	1.6	6.4	4.8	12.7	PV36A
10.3	1.6	8.0	6.4	15.9	PV44
11.1	1.6	7.2	6.4	15.9	PV837
11.1	1.6	8.0	4.8	14.3	PV50A
11.9	1.6	6.4	8.0	15.9	PV231
12.7	1.6	9.5	6.3	15.9	PV53
11.9	1.6	9.5	6.8	17.5	PV233
14.3	1.6	11.1	6.4	19.0	PV64
19.0	1.6	12.7	6.4	25.4	PV73A
20.0	1.6	16.5	6.5	25.0	PV90

MAXIMUM CONSTANT WORKING TEMPERATURE 70°C

MINIMUM CONSTANT WORKING TEMPERATURE -35°C

BLACK PVC NORMAL SHORE HARDNESS FROM 43 TO 55

**Farnell Electronic Components Limited**

Sales (0532) 636311, Technical (0532) 799123, Dataline (0532) 310160, Fax (0532) 633411, Telex 55147