

Philips  
Magic 5 Primo  
Plain paper fax  
+ telephone and copier

Primo



PPF 631



## fax it, say it

with Philips Magic 5 Primo

The Magic 5 series offers you the usual reliability of Philips plain paper faxes. Moreover it comes in a new and innovative design and is smaller than ever. Distinctive ringtones, predefined fax forms and outgoing call log are only a few of this machine's various features that will make your life easier and more comfortable.

**Reliable plain paper fax**


Stores up to 15 pages

**Feature-rich telephone**

Allows distinctive ringtones

**Easy to use copier**

With fine-/photo resolution

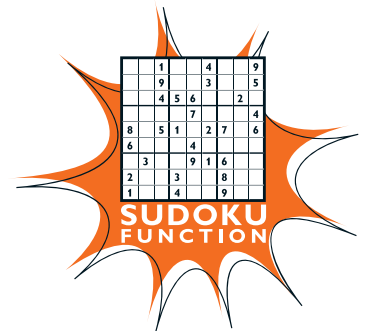

# PHILIPS

# Product Specifications

## Main features

### Ink-film fax

- ITU Group 3 compatible (T.30 standard/T.30 new)
- 9.600 bps modem speed, auto fall back
- Horizontal resolution: 8 pixels/mm  
vertical resolution standard: 3.85 lines/mm  
vertical resolution fine: 7.7 lines/mm
- Page header, automatic redial
- Sending report with reduced copy of the first page
- Printing method: thermal transfer
- 10 page automatic document feeder (ADF)
- Predefined fax forms
- Sudoku printing with solutions (easy - medium - tough - devil)
- Timer function (send later)
- Up to 15 page memory
- Group broadcasting
- Easy polling (receive and send)
- Paper tray up to 50 sheets
- Cordless phone management

### Telephone

- 50 name dial entries
- 10 ringer melodies
- Caller identification (CLIP)\*
- Distinctive ring tones\*\*
- 10 short dial keys
- On hook dialling
- Chain dialling
- Redial of the last 10 numbers
- Outgoing call log print

### Copier

- Multicopy up to 15 pages
- Fine-/photo-resolution
- Zoom-function (enlarge/reduce)
- 16 grey scales

\* Depends on the availability of the service on the local operators network

\*\* Depends on the availability of caller identification

## General information

### Power consumption

- |                          |            |
|--------------------------|------------|
| · Stand by               | typ. 1,5 W |
| · Transmission           | typ. 15W   |
| · Reception              | typ. 15W   |
| · Copy                   | typ. 15W   |
| · Telephone conversation | typ. 4W    |

### Display

- Liquid crystal-display (LCD), 16 characters/  
1 line, European characters

### Installation

- Easy-install menu and help pages

### Dimension (WxDxH)

- |            |               |
|------------|---------------|
| · Unpacked | 313x197x129mm |
| · Packed   | 377x247x200mm |

### Weight

- |                                  |       |
|----------------------------------|-------|
| · Unpacked (without accessories) | 2,4kg |
| · Packed (incl. country kit )    | 3,3kg |

### Temperature range

- |                    |                |
|--------------------|----------------|
| · Operation        | 5° C - 40° C   |
| · Storage packed   | -25° C - 50° C |
| · Storage unpacked | 0° C - 45° C   |

### Relative humidity

- |                    |           |
|--------------------|-----------|
| · Operation        | 15 - 85 % |
| · Storage packed   | 5 - 95 %  |
| · Storage unpacked | 15 - 85 % |

### Standard package includes

- Fax machine incl. cables (mains and telephone network)
- Starter ink film
- User-manual including installation-guide

### Accessories

- Philips PFA 351 with PLUG'N'PRINT Card/up to 140 pages A4

|                     |                          |
|---------------------|--------------------------|
| <b>9 NC</b>         | 288090XXX                |
| <b>Type number</b>  | PPF 631/XXB              |
| <b>EAN code</b>     | 342516017XXXX            |
| <b>Designed for</b> | PSTN/PABX                |
| <b>Power supply</b> | 195 - 264V AC/ 47 - 63Hz |

