
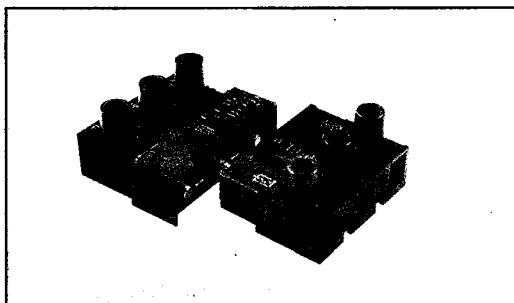


163ZEL05

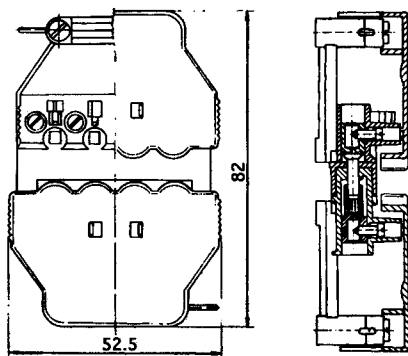

FEATURES

SERIES 160/163 plug and socket connectors are available in 2, 3 and 5 pole lengths. The shrouding of the plug connectors prevent the two parts being incorrectly assembled.

The plug section (163ST) has a leading earth pin which is 2mm longer, situated in the centre pole. The socket section (160BU) has a shroud to ensure that the plugs are totally enclosed before the earth connection is made.

Covers & base plates, **163ZEL/ABK** are available in 3 and 5 pole versions only. The cover (163ABK) can be used by snapping onto the plug or socket or both. The base plate (163ZEL) is supplied complete with an integral cord grip and screws which are supplied loose.

TECHNICAL DATA

Mouldings:	Nylon 6.6 (PA6/6) black UL94 V2
Inserts:	Plug & skt - Tinned brass
Screws:	M3 steel, zinc plated and yellow chromated
Wire protectors :	(where fitted) Stainless steel
Maximum working temp:	100° C continous
Current rating:	10 amps
Voltage rating:	380V ~
Tracking distance:	CTI > 600
Conductor size:	Without w/p - 4mm sq. With w/p - 2.5mm sq.
Stripping length:	6.5 - 7mm

APPROVALS

IMQ (F) (N) (S) (D)

EN 60320-1

