


- Very loud small horn with trumpet
- Suitable for indoor and outdoor mounting

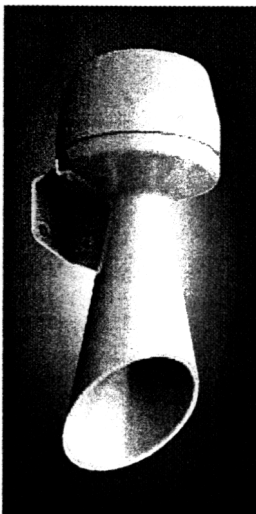

#### TECHNICAL SPECIFICATIONS:

Dimensions (Diam. x Height): 70 mm x 170 mm

Housing: ABS, high impact, grey

Connection: Screwable connection with wire protection,  
1mm<sup>2</sup> - 1.5 mm<sup>2</sup> fine strand, 1,0 mm<sup>2</sup> - 2.5 mm<sup>2</sup> single wire  
cable entry up to ø 9 mm

Duty cycle: 100 %

Fixing: Bracket mounting, Sound outlet facing downwards

#### ORDER SPECIFICATIONS:

	AC ~	Current consumption	DC =	Current consumption
12 V	-		582 052 54	150 mA
24 V	582 052 65	190 mA	582 052 55	70 mA
42 V	582 052 66	75 mA	-	
115 V	582 052 67	15 mA	-	
230 V	582 052 68	15 mA	-	

Other voltages available on request.

#### TECHNICAL DIAGRAMS

see page 117

