



MB1




MB2

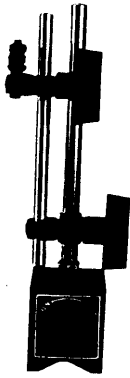

MB-SX

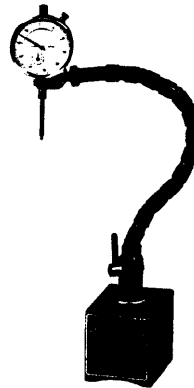

AMB-2

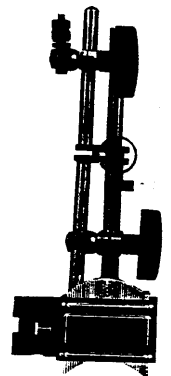

MB1 & MB2

SNAKE & ANYFORM


LINEAR magnetic base dial Indicator stands provide a comprehensive range of robust and economical tools for workshop and inspection use. Available with solid or fine adjustment cross arm. Overall height of MB-1 and MB-2 including base is 230mm. Upright arm is 12mm diameter with M8 x 1.25 thread. MB1 and MB-2 are supplied with the MB-B magnetic base. Plunger Indicators held by lug back or up to 3/8" dia. stem. Lever Indicators held by spigot.

The Snake magnetic base can be locked in any position by means of one lever. It provides clamping for plunger and lever indicators with spigots and stems between 1/8" and 1/2" diameter. The flexible arm is fitted with an MB-C which provides a pull of 80 kilos. The Anyform base is most useful on cylindrical or shaped components. The pins can be shaped to the component and then locked off and magnetised with the on/off switch.


Order Code	Product Description	Price £'s
MB - 1	Complete with magnetic base MB-B.	26.40 A
MB - 2	As above but with fine adjustment arm.	28.40 A
52-590-029	Main post 12mm dia. Thread M8 x 1.25	8.80 A
52-590-025	Main post body clamp, 12mm dia.	7.00 A
52-590-015	6" standard cross arm.	6.80 A
52-590-006	6" fine adjustment cross arm.	15.00 A
52-590-021	Universal clamp for 52-590-015 & 006	6.40 A

Order Code	Product Description	Price £'s
MB-SX	Snake arm with MB-C magnetic base	69.90 A
AMB-2	Anyform base with fine adjustment arm	104.90 A

MINI MAGNETIC BASE STANDS

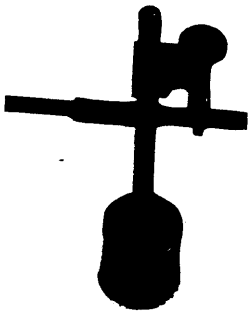

The 5086 style consists of:
 Permanent magnetic base 1" dia.. by 1" high
 Upright column 5/16 dia. by 4" long with a column clamp unit
 Double ended cross-arm with 7/32" and 1/4" dia.. ends
 The 5086FA style consists of:
 Permanent magnetic base 1" dia.. by 1" high
 Fine adjustment located on base
 Stepped upright column 3" long x 5/16" dia. reducing to 1" x 1/4" dia.
 Indicator clamp for dovetail and spigot fixing

 

Order Code	Product Description	Price £'s
5086	Mini Magnetic Base	25.95 A
5086-FA	Mini Mag. Base with Fine Adjustment	26.95 A



MB - A



MB - B



MB - C



DG0038



DG0039

MAGNETIC BASES

Order Code	Description	Pull (kgs)	H	W	L	Price £'s
MB-A	Anyform On/Off base	20	50	70	50	92.95 A
MB-B	On/Off Switch base	40	45	70	50	17.00 A
MB-C	On/Off Switch base	80	57	51	62	28.80 A
DG0038	On/Off Switch base	100	50	75	55	69.95 A
DG0039	On/Off Switch base	130	50	120	55	118.90 A
NF0037	On/Off Switch base	32	35	30	40	23.45 A
NF0140	Permanent base	28	16	60	32	15.40 A



NF0037



NF0140