


Circuit Protection

534 - 456 TO 535

L562

Size 00 miniature glass fuse links.
15,9 mm x 4,7 mm
($\frac{5}{8} \times \frac{3}{16}$ inch diameter)

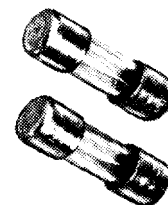


This range of miniature fuse links is widely used for circuit protection in the telecommunications and electronics industries.

Ratings from 50 mA to 150 mA blow within 10 seconds at three times rated current. Ratings from 250 mA to 7 A blow within 10 seconds at two times rated current.

Breaking capacity: _____ See table below
Life: _____ 1,000 hours continuous at rated current at 25 °C
Marking: _____ Rated value on cap

Ordering reference: _____ L562/current rating in amperes

Rating	Rated voltage	
	d.c. *	a.c. **
50 mA	900 V	250 V
100 mA	900 V	250 V
150 mA	600 V	250 V
250 mA	600 V	250 V
350 mA	300 V	250 V
500 mA	300 V	250 V
1 A	200 V	150 V
2,5 A	150 V	150 V
4 A	60 V	60 V
5 A	60 V	60 V
7 A	60 V	60 V

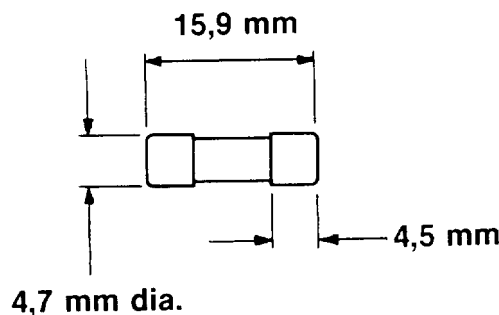

*Based on maximum breaking capacity at 10 In rating.

**Based on maximum breaking capacity at 10 In rating or 35 A whichever is the greater.

ORIG