


SF 1070	Rated Current A	Leakage Current @ 250V 50Hz	Inductance mH		Connections		Approvals		
			L1	L2	Input	Output	UL	CSA	SF
SF 1070-1/01	1	0.2mA	4.5	0.3	IEC 320	6.3 x 0.8 Faston	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>
SF 1070-1/03	1	0.2mA	4.5	0.3	IEC 320	Solder Tag	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>
SF 1070-3/01	3	0.2mA	1.2	0.3	IEC 320	6.3 x 0.8 Faston	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>
SF 1070-3/03	3	0.2mA	1.2	0.3	IEC 320	Solder Tag	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>
SF 1070-6/01	6	0.2mA	0.5	0.3	IEC 320	6.3 x 0.8 Faston	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>
SF 1070-6/03	6	0.2mA	0.5	0.3	IEC 320	Solder Tag	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>

Temperature Range: -25°C to +85°C
 Operating Voltage: 250Vac
 Operating Frequency: 0 to 400Hz
 Test Voltage: L+N to ground, 2700Vdc, 2 seconds

Approved
 Submitted for Approval

DIMENSIONS

All dimensions are nominal and in mm

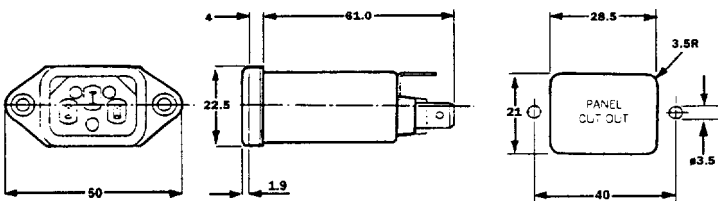

CIRCUIT DIAGRAM

