

 


Section: **Cable**

Sub Section: **Van Damme audio cable range**

Product: **Van Damme blue series pre-jacketed ofc multicore**

 

 Continue Shopping	 View order	 Add to cart
---	---	---

Choose a configuration (s), specify the quantity and click the 'Add to cart' button.

- Click 'View order' to proceed to the order screen, confirm the

Van Damme blue series pre-jacketed ofc multicore

The Van Damme Oxygen Free Copper blue series multicore is the flagship of the range. VDC designed this cable considering all your requests, ideas and problems, to satisfy the increasing demand for a more comprehensive range of multicores. It took 3 years of research and development to perfect the definitive level of quality found in this range of cables. The blue series combines many unique

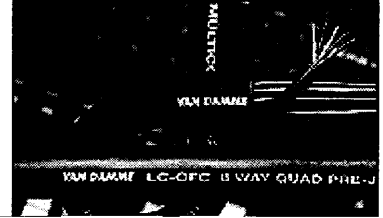

Technical Specification

Pair conductor:	28 x 0.10mm (0.22mm ²) 24 AWG high purity plain OFC
Pair insulation:	Cross linked polyethylene (XLPE) - 1.00mm diameter
Screen:	Aluminium polyester foil tape - free edge foil (FEF)
Drain wire:	19 x 0.12mm (0.22mm ²) 24 AWG high purity tinned OFC
Pair jacket:	Highly flexible PVC numbered cores - 2.70mm dia.
Overall jacket:	Abrasion resistant special PVC composite
Jacket colour:	Matt petrol blue - RAL 5001
Temp. range:	-25°C ~ +70°C
Colour code:	IEC + Van Damme extension (lines 37 to 48)
D.C. resistance:	< 85W/km
Capacitance:	< 100pF per metre core to core < 200pF per metre core to core + screen
Inductance:	0.5uH per metre
Voltage rating:	250V

Stock code	No. Pairs	O.D.	Weight	Jacket Thickness	M Len
268-202	2	7.5mm	68kg/km	1.0mm	10
268-204	4	9.6mm	105kg/km	1.5mm	10
268-208	8	12.2mm	175kg/km	1.5mm	10
268-212	12	14.3mm	228kg/km	1.5mm	10
268-216	16	16.3mm	310kg/km	1.8mm	5
268-224	24	20.8mm	480kg/km	2.0mm	5
268-232	32	22.1mm	590kg/km	2.0mm	5
268-240	40	25.0mm	720kg/km	2.1mm	5
268-248	48	26.3mm	855kg/km	2.1mm	5