

PACINTEC®


4.0"




The RC Series offers two unique handheld enclosure designs, with a low-profile appearance and ruby infrared lens. The WM Series is a new vertical and horizontal wall-mountable housing with a display area ideal for a wide variety of wall-mounted systems and controls. Customization areas permit inexpensive changes to exterior styling and modifications for LCDs and keypads.

STANDARD OPTIONS

- Insert tooling areas
- Ruby infrared lens (RC only)
- Battery compartment
- EMI/RFI shielding
- Standard and custom membrane switches
- Custom panels & overlays
- Belt clip (RC only)
- Wrist strap (RC only)
- Flame retardant materials
- Connector cutouts

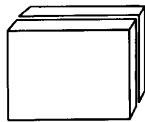

WM

 

RC SERIES	WIDTH	LENGTH	HEIGHT	BELT CLIP
RCS-23-2AA	1.94	2.94	0.70	
RCS-24	2.50	4.60	0.70	
RC24	2.50	4.60	0.80	
RC-24-9VB/2AA	2.50	4.60	0.90	RC-24-9VB/2AA-BC
RCS-24-9VB/2AA	2.50	4.60	0.90	RCS-24-9VB/2AA-BC
RC-35-9VB/2AA	2.50	4.95	0.90	
RC-37-9VB	2.75	6.50	0.80	
RF SERIES	WIDTH	LENGTH	HEIGHT	
RF15/2AA	1.50	5.70	0.70	
RF35	2.95	5.00	0.83	
RF37	2.95	6.77	0.83	
RF37/9VB	2.95	6.77	0.93	
WM SERIES	WIDTH	LENGTH	HEIGHT	
WM-34	3.00	4.00	0.80	
WM-46	3.75	5.25	1.00	
WM-68	6.00	7.95	1.00	
WM-810	8.00	10.00	1.40	

All dimensions are outside dimensions—in inches