


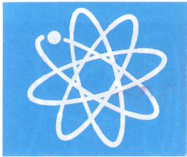

SANDVIK BELZER

"Electronique" double open-end spanner set Metric

1933M-Set



Finish: nickel and chrome-plated, polished.

Material: SPECIAL STEEL.

Angle 15°.

One end 10° offset. Equal openings at both ends. Extra long and slender type for all work on electronic appliances, office machines, telegraphy and telephony, etc.



As per DIN 934.

In blue plastic wallet.

Product code	EAN code 731415+		No. units	Dim. mm	
1933M/6T	1821654	1	6	4x4 4,5x4,5 5x5 5,5x5,5 6x6 7x7	70

Liliput combination spanner Metric

4020L-M

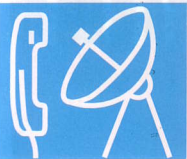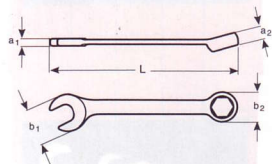

Finish: nickel and chrome-plated, fine-polished.

Material: VANADIUM-EXTRA.

Open-end angle 22.5°.

Box spanner end: hexagon, angle 15° offset.

Equal openings at both ends.

For radio, telecommunications, electrical and precision engineering, carburetors, etc.

Product code	EAN code 731415+		Dim. mm	L mm	a ₁ /a ₂ mm	b ₁ /b ₂ mm	
4020L-M-3	1077693	5	3	70	2,3x2,5	9 x7,5	6
4020L-M-3.2	1405038	5	3,2	70	2,3x2,5	9 x7,5	6
4020L-M-3.5	1077709	5	3,5	70	2,3x2,5	9 x7,5	6
4020L-M-4	1077716	5	4	70	2,3x2,5	9 x7,5	6
4020L-M-4.5	1077723	5	4,5	80	2,5x4	11,5x9	9
4020L-M-5	1077730	5	5	80	2,5x4	11,5x9	9
4020L-M-5.5	1077747	5	5,5	80	2,5x4	11,5x9	9