

SKINTOP® CLICK BLK

Plastic blind plugs



SKINTOP® CLICK BLK

Application

Blind plug with innovative CLICK system for fast installation in hardly accessible places. Perfect solution wherever threads previously cut must be closed.

Developed especially for:

- Manufacturing of control cabinets
- Measurement, control and electrical applications
- Automation technology
- Plant, apparatus construction


- Control system construction

Advantage

- Up to 70% time saving due to innovative snap-in system
- Simple, free assembly in any position
- Fewer parts, counter nut no longer needed
- Captive
- No thread required
- Maximum quality
- IP 68, hermetically sealed

Note

- Disassembly tool contained in the delivery scope

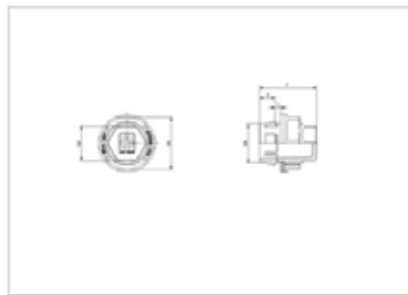

Technical Data



Approvals
Wall thickness 1-2 mm with VDE approval
Wall thickness 1-4 mm VDE in preparation



Colour delivered
RAL 7035 light grey



Material
Body: special polyamide
Seal: special elastomer



Degree of protection
IP 68



Range of temperature
-20°C up to +100°C

Part number	Part designation / size	S (wall thickness mm)	M (hole mm)	SW1 / SW2 mm	D mm	C mm	PU pieces
SKINTOP® CLICK BLK light grey							
52109013	CLICK BLK 16	1 - 2	16,3 (-0,2)	14 / 22	8	28,5	50
52109014	CLICK BLK 20	1 - 2	20,3 (-0,2)	18 / 27	8	29,5	25
52109015	CLICK BLK 25	1 - 2	25,3 (-0,2)	22 / 34	8	30,5	25