

* 317 2960
(888 3619)

AEG HOT AIR GUNS


AEG hot air guns feature high heat output and precise temperature adjustment to suit the material being worked on. They are ideal for dust-free removal of old paint which would otherwise have to be stripped with chemicals, or

manually scraped off. The AEG hot air guns can also be used for sealing and shaping plastics, for reliable, easy application of edge bands, for tin-plate application and even for soft soldering of copper pipes.



HOT AIR GUN POWER THERM 560

- Versatile air gun for stripping old paints, moulding and welding plastic, soft soldering and applying tin-plate coatings
- High 1500 watt heat output with two temperature settings (300°/560°)
- Robust fan for continuous operation
- Non-slip standing surface for stationary use

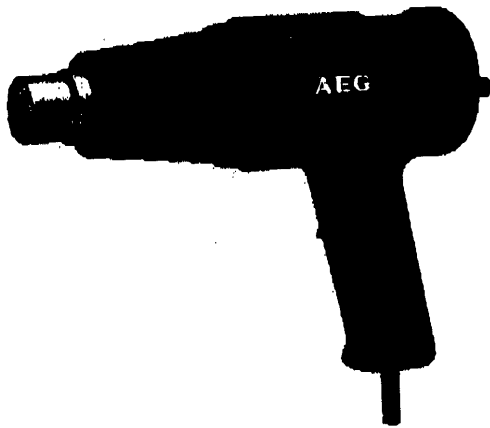

HOT AIR GUN POWER THERM 600 EC *

- Electronics with temperature sensor control for variable temperature settings ranging from 90° to 600°
- 2000 watt heat output
- Same other features as Powertherm 560

600EC ONLY FOR
UK



		1500	2000
Power Input	Watt	400/450	300/500
Air flow	l/min	150/560	90-600
Temperature control	°C	0.6	0.6
Weight of tool	kg	3450 48	3450 44
Article number	4935-	10679 0	10680 6
EAN code	4002395		