


STANLEY E LEVEL


- Girder section level for the DIY'er
- 2 plumb, 1 horizontal permanently fixed all round visibility vials
- Easy clean epoxy finish

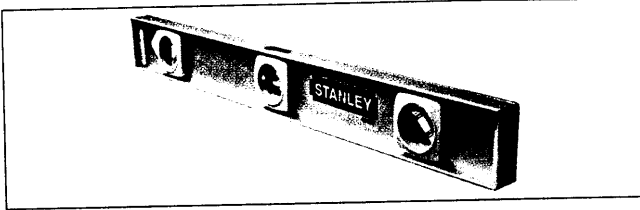

STANLEY	i			
1-42-072	300 mm, 3 vials		1	3253561420726
1-42-073	450 mm, 3 vials		1	3253561420733
1-42-074	600 mm, 3 vials		1	3253561420740
1-42-075	900 mm, 3 vials		1	3253561420757
1-42-076	1200 mm, 3 vials		1	3253561420764

CANOE LEVEL

- Classic craftsman's small level
- Horizontal and plumb vials

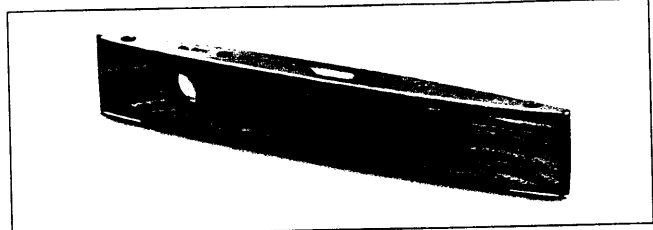


STANLEY	i			
0-42-861	230 mm, 2 vials	x	6	3253560424657

FOAMCAST LEVEL

NEW


- Lightweight and shock resistant ABS Structure
- 0°, 90° and 45° vials for improved accuracy
- Easy to carry open frame
- Bright colour accents - easy to find on site
- Top read center vial

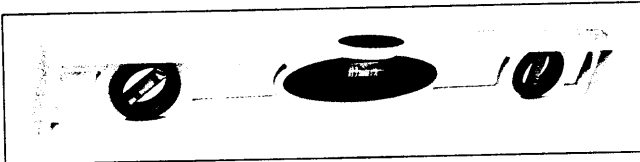

STANLEY	i			
1-42-474	300 mm, 3 vials		6	3253561424748
1-42-475	450 mm, 3 vials		6	3253561424755
1-42-476	600 mm, 3 vials		6	3253561424762
1-42-478	1200 mm, 3 vials		6	

LINE LEVEL


- Metal body with line hooks

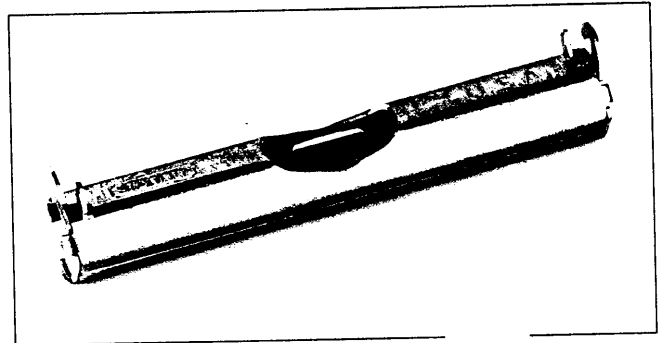

STANLEY	i			
0-42-287	80 mm, 1 vial	x	6	076174422870

TORPEDO LEVEL, ALUMINIUM


- Combines accuracy and lightweight, ideal for all small installations
- 3 vials: horizontal, plumb and 45°

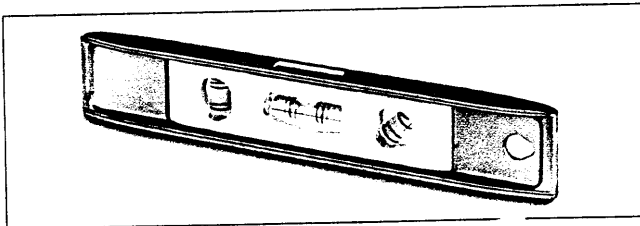

STANLEY	i			
0-42-465	230 mm, 3 vials	x	6	3253560424657

TORPEDO LEVEL, PLASTIC

- Handy and economical
- 3 vials: horizontal, plumb and 45°

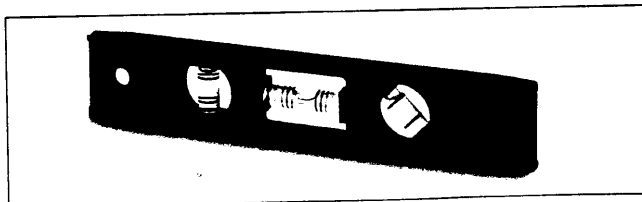

STANLEY	i			
0-42-294	200 mm, 3 vials	x	6	3253560422943

ESTIMATOR

- Ultrasonic measurement up to 32 feet / 10 metres
- Tough carrying case
- English and metric reading options
- Digital display
- Accurate to within 1%



STANLEY	i			
0-39-032		x	6	3253560390327