



REDUCED SHANK PHILLIPS BITS ⊕

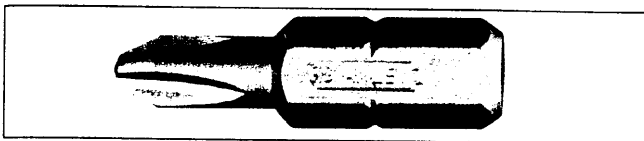

STANLEY	⊕			
3-68-728	2 pt		100 x 1	3253563687288

MAGNETIC BIT HOLDER

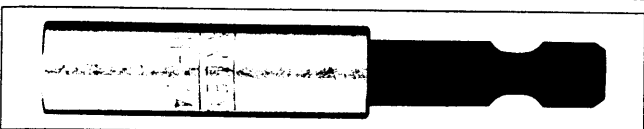


STANLEY	i			
0-68-732	60 mm	x	1 x 1	3253560687328
1-68-732	60 mm		5 x 1	3253561687327

MAGNETIC BIT HOLDER - LOCKABLE QUICK RELEASE


STANLEY	i			
1-68-733			5	3253561687334

BIT SETS

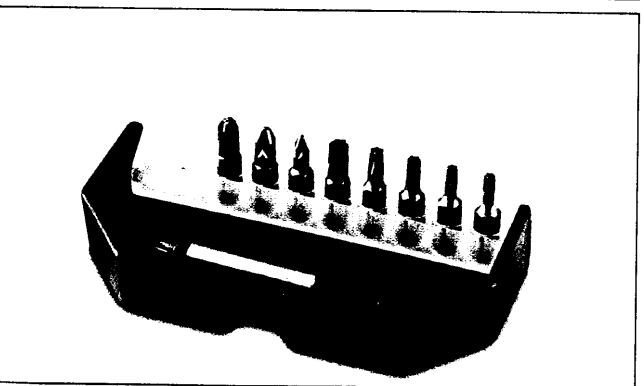


STANLEY	i			
1-68-724	10 pc	x	1	3253561687242
1-68-734	10 pc	x	1	3253561687341
1-68-735	7 pc	x	1	3253561687358
1-68-737	7 pc	x	1	3253561687372
1-68-738	7 pc	x	1	3253561687389
1-68-739	7 pc	x	1	3253561687396
1-68-741	200 pc		1	3253561687419

1/4" HEX DIRECT DRIVE SOCKET ADAPTOR

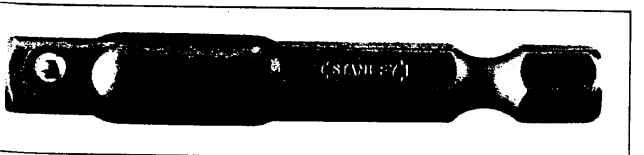

STANLEY	i			
1-68-799	50 mm		10 x 1	3253561687990


1/4" HEX BIT HOLDER - MAGNUM

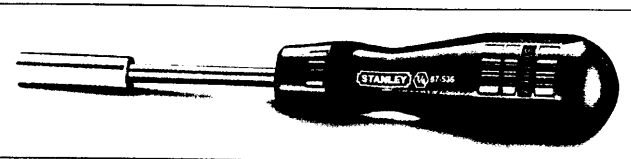

STANLEY	i			
1-67-536	100 mm		6	3253561675362
1-67-537	200 mm		6	3253561675379

RUSSIAN PINCERS LACQUERED HANDLES


- High grade alloy steel
- Induction hardened cutting edges
- Conforms to ISO 9242 and DIN 5242 standards

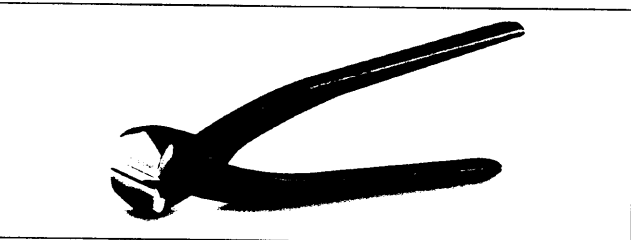

STANLEY	i			
2-84-302	220 mm	x	6	3253562843029

CARPENTERS PINCERS


- High grade alloy steel pincers with precision broached jaws and cutting edges
- Flat handles for comfort in use
- Conform to ISO 9243 and DIN 5241 standards

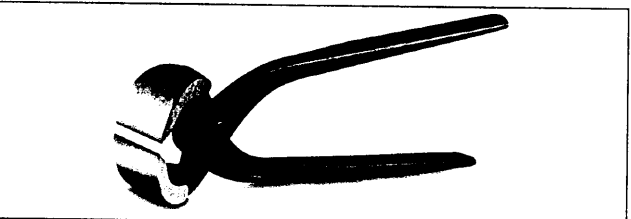

STANLEY	i			
2-84-183	180 mm	x	6	3253562841834
2-84-184	225 mm	x	6	3253562841841
2-84-185	250 mm	x	6	3253562841858

G CLAMP

- Fine grained cast iron
- Reinforced corners
- Plated screw for a smoother action

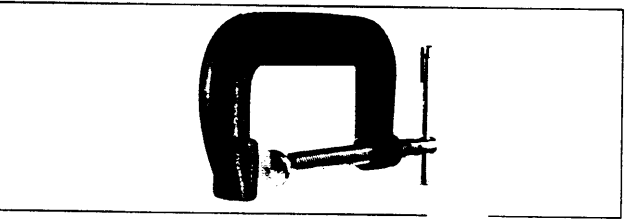

STANLEY	i			
1-83-502	50 x 30 mm		6	3253561835025
1-83-503	75 x 52 mm		6	3253561835032
1-83-504	100 x 60 mm		6	3253561835049
1-83-505	125 x 68 mm		6	3253561835056
1-83-506	150 x 75 mm		6	3253561835063
1-83-508	200 x 83 mm		6	3253561835087

7
1
4
8
5

74
81
98
88

585
592
608
615
622
639
646
653
660
677
684

2