


Pocket Mini 110mm(4") Laser Level

● Class II 645nm Laser, 6mm Dot upto 150 metres

Pro-level™ Digital Spirit Level

● Audible and visual indication of level with 2 conve bubble level indicators

 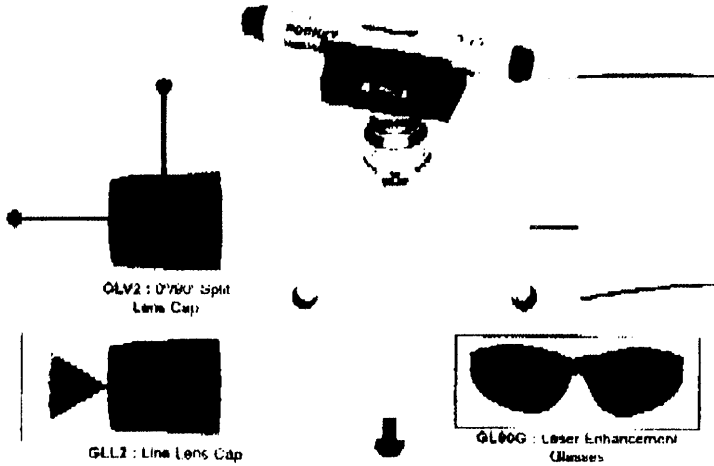


An Ideal aid and tool for horizontal levelling, pipe aligning, installations and marking out applications. The laser level has a hexagonal heavy metal case and has a centrally located green level bubble. The polycarbonate holder also has a green level bubble with an open hexagonal void and heavy-duty snap fit shoulders for fitting the laser level. The holder has a standard 1/4" camera bush for tripod mounting.

The Pro-level™ is a quality precision instrument with advanced e. Housed in a robust polycarbonate ABS plastic case with rotating angle measurement indicators. Vertical and horizontal planes can be determined via 2 traditional green bubble level indicators.

- Class II 645nm Laser output.
- 6mm dot upto a distance of 150 metres.
- Each tripod leg has soft touch rubber feet for firm and stable positioning.
- The tripod is lightweight and rugged. The legs have telescopic adjustment to facilitate level alignment on uneven surfaces.
- Supplied with laser level, holder, tripod, batteries and instructions for use.
- GLV2 lens cap splits the laser beam prism into two, giving both a 0° and a 90° output point.
- GLL2 lens cap has precision optics, which deflects the laser to form a single projected line upto 5 metres.
- GL90G are laser colour spectrum enhancement glasses, for use in bright conditions, having the effect of enhancing the intensity of the laser dot or line.

- Measures vertical and horizontal planes.
- Precise LED indicator - Green equals level - 2 x Red off level right or left.
- Audible signal warns off level which allows measurement where vision is restricted.
- Rotation ruler cm and inches and protractor with corresponding angle degree setting indicators.
- Ruler/protractor screw to prevents accidental change set angles.
- 3 way sliding power switch (silent/on (audible)
- Hi-accuracy of ±0.3° from level.
- Supplied with battery and instructions for use.



Under Ground Levelling




Cutting Guide



Indoor Alignment



Vertical and Horizontal Setting out

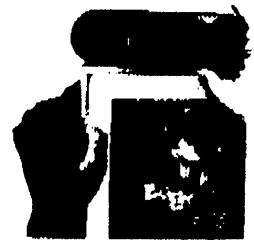

Technical Specifications

Laser	Class II 645nm
Output	6mm point/4mm line
Power	3 x 1.5V PL-13 Button Cell Battery
Dimensions	110 x 14mm Ø unit
Weight	225g

Technical Specifications

Indication of level	Green LED
Accuracy	±0.3° from true level
Power	1 x 9V PP3 Battery
Environmental	0° - 60°C
Dimensions	200 x 60 x 20mm
Weight	185g

Model No.	Description
GL90D2	Mini Laser Kit
GLV2	0°/90° Split Beam Lens
GLL2	Line Beam Lens
GL90G	Laser Enhancement Glasses
GPL-13-3	1.5V PL-13 Button Battery Cell (3 pack)

Model No.	Description
GSW-115B	Digital Spirit Pro-Level™
GEBF-22	1.5V PP3 Heavy Duty Battery