

COMMONWEALTH ACCESSORIES


550-772 to 551-089

FP-108-1


119x119x38mm

DESIGN FEATURES


- *BEARING SYSTEM: SLEEVE BEARING & BALL BEARING
- *WEIGHT: 550 (g)
- *IMPELLER: PLASTIC WITH FIBER GLASS FILLED UL 94V-0
- *HOUSING: DIE CAST ALUMINUM PAINTED BLACK OR NATURAL COLOR
PBT PLASTIC UL 94V0
- *MOTOR: SHADED POLE, IMPEDANCE PROTECTED
- *CONNECTING: TERMINAL & WIRE LEADS
- *SPEED: S-1 HIGH SPEED TYPE
S-2 MEDIUM SPEED TYPE
S-3 LOW SPEED TYPE
- *OTHER VOLTAGE 24, 48, 100, 380 (50/60HZ) ARE AVAILABLE

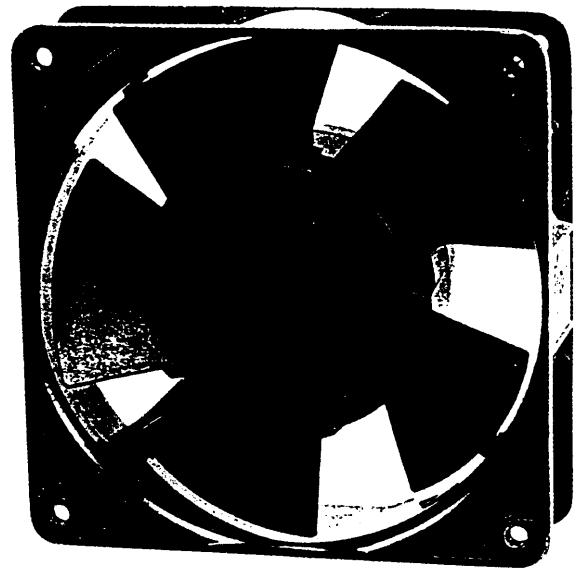

DIMENSIONS

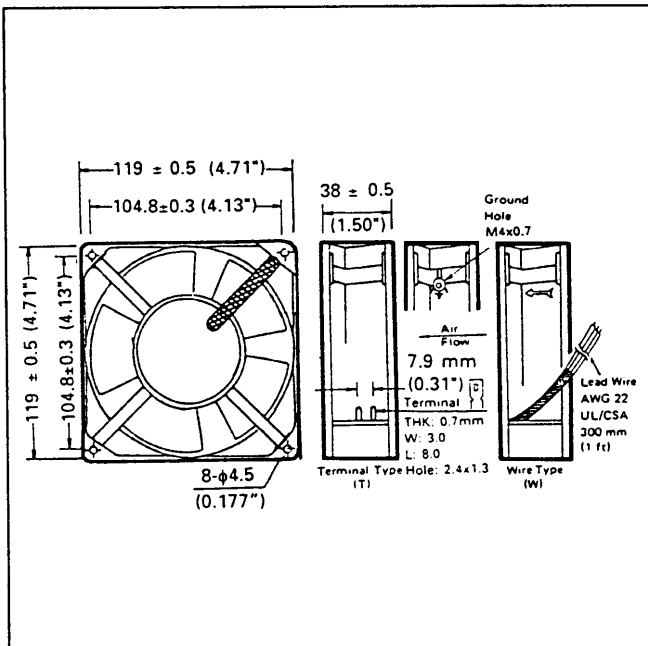

PERFORMANCE

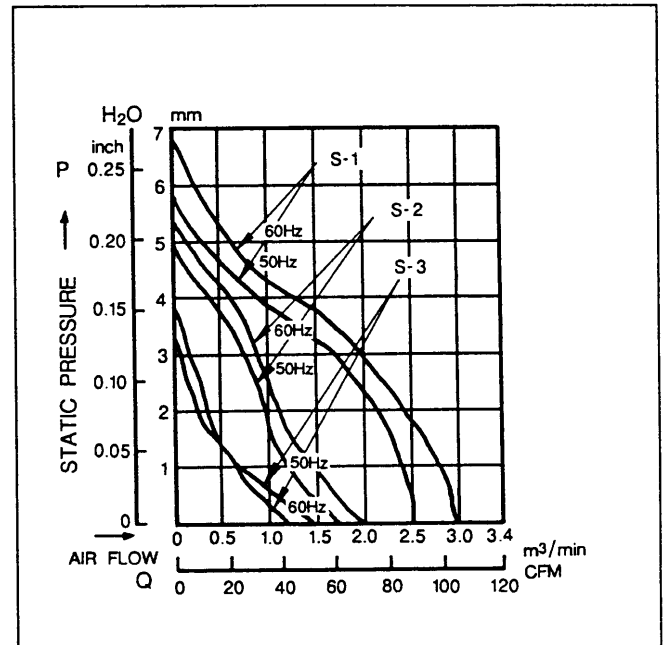

SPECIFICATIONS

Model No.	Volt (VAC)	Frequency (HZ)	Air (CFM)	Volume (M ³ /Min)	Current (A)	Power (W)	Speed (RPM)	Static pressure (Inch- H ₂ O)	Nosie (dBA)
FP-108-1 (S-1)	110/120	50/60	80/105	2.3/3.0	0.24/0.18	18/17	2700/3000	0.23/0.28	42/47
FP-108-1 (S-1)	220/240	50/60	80/105	2.3/3.0	0.12/0.11	18/17	2700/3000	0.23/0.28	42/47
FP-108-1 (S-2)	110/120	50/60	63/71	1.65/1.85	0.13/0.12	11/10	2100/2300	0.19/0.21	37/39
FP-108-1 (S-2)	220/240	50/60	63/71	1.65/1.85	0.12/0.10	11/10	2100/2300	0.19/0.21	37/39
FP-108-1 (S-3)	110/120	50/60	54/52	1.5/1.4	0.14/0.12	9/8	1600/1800	0.16/0.15	30/34
FP-108-1 (S-3)	220/240	50/60	54/52	1.5/1.4	0.07/0.06	9/8	1600/1800	0.16/0.15	30/34