




PRODUCT CATALOG

9.6 Volt Cordless

DA391DW 3/8" Cordless Angle Drill Kit Variable Speed, Reversible

Features

- Ideal for close quarter drilling or driving; measures only 4-1/2" from tip of chuck to widest portion of tool body
- Variable speed (0 - 800 RPM) for pinpoint hole positioning
- Keyless chuck for fast and easy bit installation
- Electric brake stops chuck quickly
- Compact, well balanced and light weight (2.9 lbs.) for easy maneuverability
- Overload protector helps prevent motor burnout

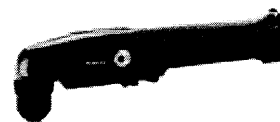

(Click for larger view)

Standard Equipment

- Battery (632007-4)
- Charger (113103-2)
- Keyless chuck (763083-8)
- Plastic tool case (182425-A)

Specifications

Capacities:	Steel	3/8"
	Wood	15/32"
	Wood screw	#9 x 3/4"
No load speed		0 - 800 RPM
Max. tightening torque		43.4 in.lbs.
Battery		9.6VDC (1.3Ah)
Overall length		13-1/4"
Net weight		2.9 lbs. (w/battery)
Shipping weight		9.0 lbs.



[To Product Listing](#)