

531 224
 236
 plus
 388
 479

Type	Side Walls	Pg Knockouts	Inside Height	Ref. No.	Unit
POLYSTYRENE - COVER GREY RAL 7035					
PS 99- 6	with Pg		45 mm	115-403	40/4
PS 99- 8	with Pg		69 mm	115-903	30/3
PS 99- 6-o	smooth		45 mm	110-403	40/4
PS 99- 8-o	smooth		69 mm	110-903	30/3
POLYSTYRENE - COVER TRANSPARENT					
PS 99- 6-t	with Pg		45 mm	116-003	40/4
PS 99- 8-t	with Pg		69 mm	116-503	30/3
PS 99- 6-to	smooth		45 mm	111-003	40/4
PS 99- 8-to	smooth		69 mm	111-503	30/3
POLYCARBONATE - COVER GREY RAL 7035					
PC 99- 6	with Pg		45 mm	125-403	40/4
PC 99- 8	with Pg		69 mm	125-903	30/3
POLYCARBONATE - COVER TRANSPARENT					
PC 99- 6-t	with Pg		45 mm	135-003	40/4
PC 99- 8-t	with Pg		69 mm	135-503	30/3



TK 99
Empty
Enclosure
94 x 94^{mm}
Type of
Protection
IP 66

Knockouts: = Pg 16/11 = Pg 16 = Pg 21/16 = Pg 29/21


Pg	Max. number of Pg drill holes per box side	
	A	B
7	3	3
9	2	2
11	2	2
13.5	2	2
16	2	2
21	-	-
29	-	-
36	-	-

All dimensions in millimeters

TK 99
 A winner -
 universal thanks
 to the generous
 range of
 accessories
 and various
 cover heights.

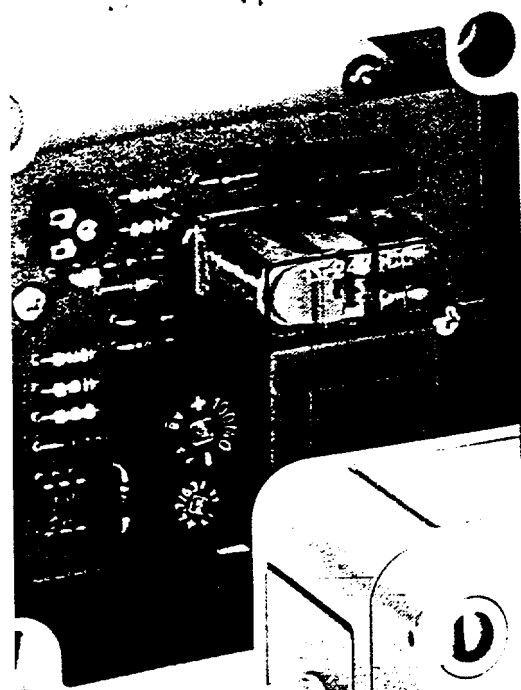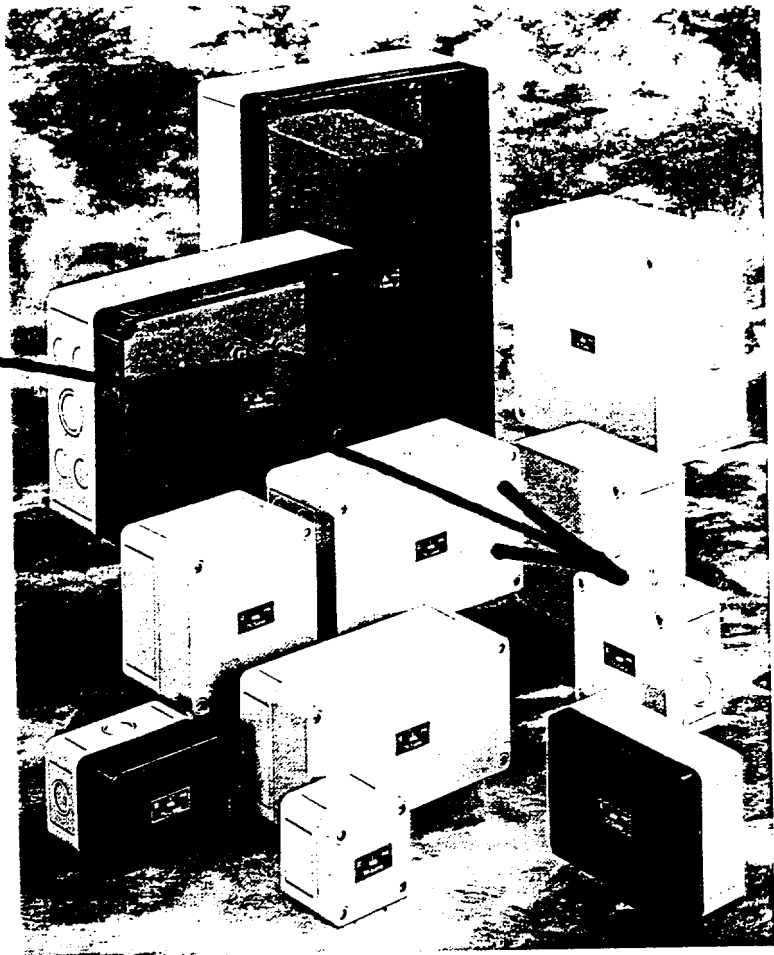

<i>Description</i>	<i>Ref. No.</i>	<i>Page</i>
Mounting plate	195-003	61
Mounting rail TS 15/75	Z-630	61
Hinge kit	190-002	61
Wall plate kit	194-001	61

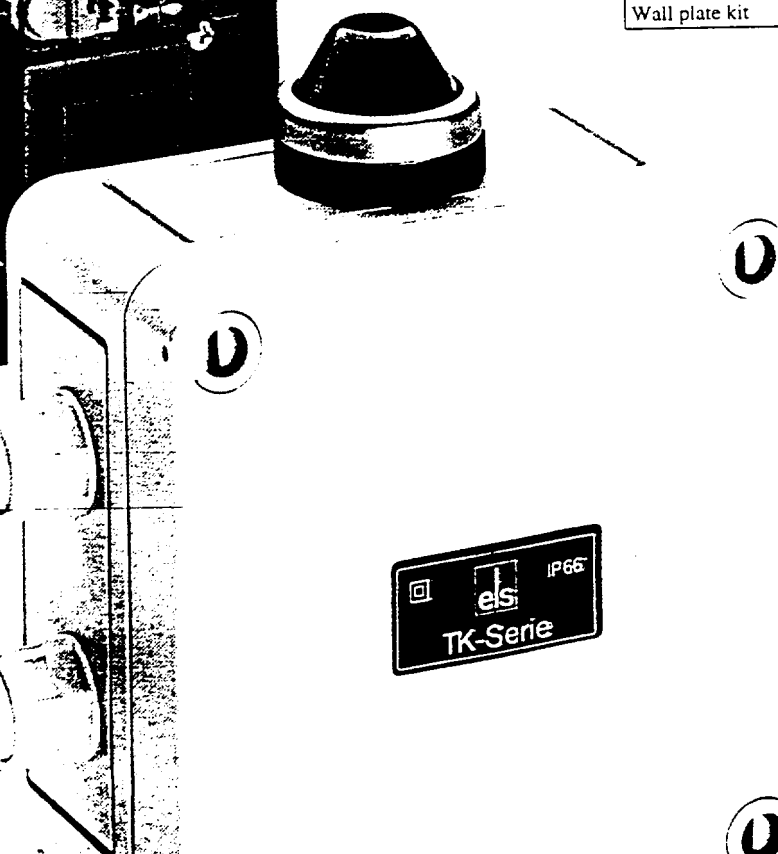

A complete
 overview
 of the system
 accessories
 is given
 on pages
 58 - 63.