


SPECIFICATION

RATED VOLTAGE 250V
 CURRENT 16A AT 40 Deg. C
 FREQUENCY 50/60Hz
 TEMPERATURE RANGE -25 TO 85 Deg. C
 LEAKAGE CURRENT 6.2mA AT 250V 50Hz
 TEST VOLTAGE 2kV DC

MINIMUM INSERTION LOSS

Frequency Hz	30k	100k	150k	300k	10M
Common Mode dB	13	55	70	>80	>80
Differential dB		31	45	>55	>55

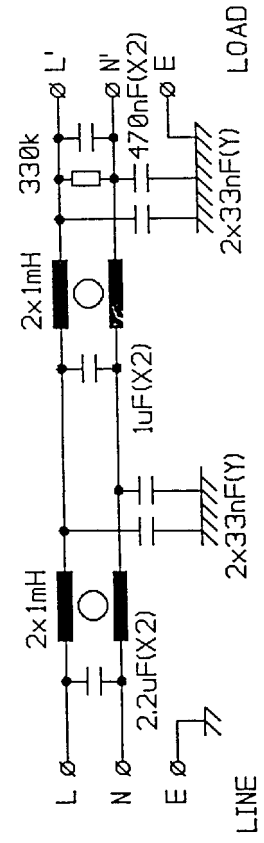

ROXBURGH

Roxburgh Electronics Ltd
 Roxburgh House
 Foxhills Industrial Park
 Scunthorpe
 South Humberside DN15 8QJ
 Tel: 0724 281770
 Fax: 0724 270230
 Telex: 52405

Title TWO STAGE MAINS FILTER
 250V 16A 50/60Hz

Page 1 of 1
 Drg No. MDF16-GS

ISSUE	1	CIN	--	DATE	6/5/93	DRAWN	SW	APPROVED
-------	---	-----	----	------	--------	-------	----	----------