
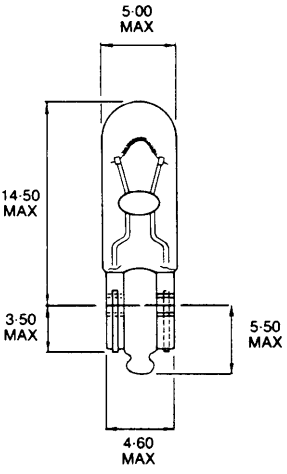


SUB-MINIATURE LAMPS

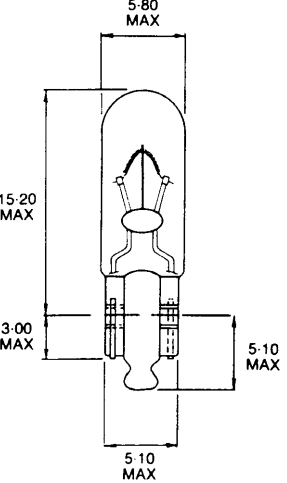

T-1 1/2	5mm	Lamp Number	Volts	Amps/Watts	Lumens	MSCP	Life (hours)	Filament Shape		
Wedge Base (W2×4.6d) 	1103	6.0	0.03A	0.30	0.024	3,000	C-2R			
	1104	6.0	0.08A	0.90	0.07	5,000	C-2V			
	1105	6.0	1.0W	3.80	0.30	5,000	C-2R			
	1107	12.0	0.03A	0.70	0.056	3,000	C-2V			
	1108	12.0	1.0W	3.00	0.24	5,000	C-2V			
	286	12.0	1.2W ¹	7.20 ¹	0.60 ¹	1,000 ¹	C-2V			
	1182	12.0	1.5W	5.30	0.42	5,000	C-2F			
	924	12.0	2.0W	7.50	0.60	1,000	C-2F			
	1109	13.0	0.10A	7.50	0.60	1,000	C-2V			
	1145	18.0	0.04A	1.90	0.15	10,000	C-2F			
	1110	24.0	0.03A	1.25	0.10	5,000	C-2F			
	1111	24.0	1.0W	3.00	0.24	7,000	C-2F			
	508	24.0	1.2W ²	6.25 ²	0.50 ²	1,000	C-2F			
			¹ at 13.5V ² at 28V							
	FIG.17									
	T-1 3/4	6mm	Lamp Number	Volts	Amps	Lumens	MSCP	Life (hours)	Filament Shape	
	Wedge Base 	CM84	6.3	0.04	0.25	0.02	10,000	C-2V		
		CM86	6.3	0.20	5.00	0.40	20,000	C-2V		
CM73		14.0	0.08	3.80	0.30	15,000	C-2F			
CM37		14.0	0.09	6.30	0.50	1,500	C-2F			
CM85		28.0	0.04	3.80	0.30	7,000	C-2F			
FIG.18										