



DNH^{AS}

**N-3770 Kragerø
NORWAY**
Phone: (47) 35 98 56 00
Fax: (47) 35 98 56 10
E-mail: dnh@dnh.no
Web-site: www.dnh.no

**DNH WW Ltd.
England**

Phone:.....(44) 1908 275 000
Fax:.....(44) 1908 275 100
E-mail:.....dnh@dnh.co.uk

**DNH GmbH
Germany**


Phone:.....(49) 040 6569 30-0
Fax:.....(49) 040 6569 30-30
E-mail:.....dnh@dnh.de

**DNH
Speakers Inc.
USA**


Phone:.....(1) 484 494 5790
Fax:.....(1) 484 494 5793
E-mail:.....dnh@dnhspeakers.com

ISO 9001 CERTIFIED

BPF-560(T)

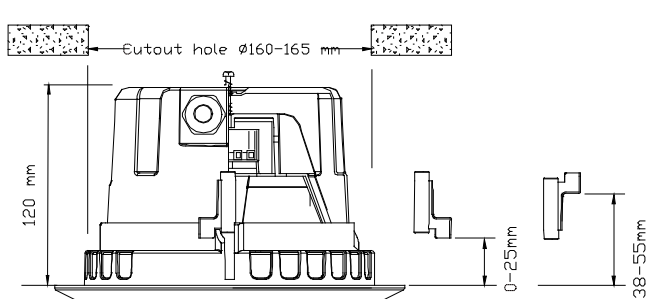

M20 cable gland and M20 blinding plug

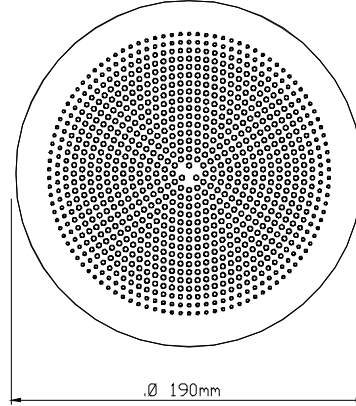

Transformer:
Combined
70/100Volt line
White : Red 100 V
White : Green 70 V

Secondary nominal
tappings:
C : 6 6,0 W
C : 3 3,0 W
C : 1,5 1,5 W
C : 0,5 0.5 W

SPL at different frequencies at 1W/1m sine wave (P-5/15B)



Material / Color PA ABS / RAL9010
Mounting Hooks
Termination Spring clamp
Weight w/ transformer 0,9 kg
IP-rating.....
Max / min amb temp 90°C / -20°C
Rated / max power 6 W / 10 W
SPL 1W/1m 90 dB
SPL rated power 97 dB
Effective freq range 130 – 15000 Hz
Dispersion (-6dB) 1kHz / 4kHz 170° / 60°
Options Impedance, color, label

Installation, Operation and Maintenance Procedures

- When mounting the loudspeaker please ensure that it is re-assembled in the same manner in which it was received.
- Hooks can be mounted both ways, see drawing at top of the page.
- For optimum performance, always use the correct voltage / power and operate within the frequency limits as stated.
- Take care when loudspeaker is energized (100V or 70V)
- Do not open loudspeaker when energized.
- This loudspeaker is supplied with a 2 year warranty against defective workmanship.