


7289911

September 1997

# Information Sheet DAT00054

CS01035

## Mustek Flatbed Scanner (CS01035)

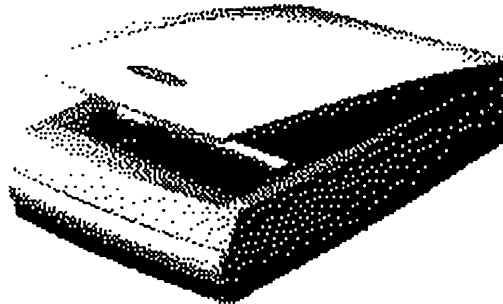

### Specification

<b>Modes:</b>	<b>True Colour:</b> 30 bit internal 1.074 billion colours 24 bit external 16.7 million colours
	<b>Gray Mode:</b> 10 bits internal 1024 shades of gray 8 Bits external 256 shades of gray
	Text/Line Art
<b>Scanning Method</b>	1 scanning pass  1 bit/pixel
<b>Scan Area (Max.)</b>	216 x 292mm
<b>Resolution</b>	Optical: 300dpi (H) x 600dpi (V) Max. 4800pi x 4800dpi (software Interpolation)
<b>Scanning Data Buffer</b>	32Kb Max.
<b>Gamma Correction</b>	Downloadable by Software
<b>Brightness Control</b>	255 Adjustable Steps (software controlled)
<b>Contrast Control</b>	255 Adjustable Steps (software controlled)
<b>Interface</b>	EPP
<b>Light Source</b>	Cold Cathode Lamp
<b>Dimensions</b>	43.9cm x 29.9cm x 85.5mm (L x W x H)
<b>Weight</b>	3Kg (6.6 lbs)
<b>Voltage Requirements</b>	100Vac-250Vac 63Hz
<b>Power Consumption</b>	15W (Max.) 15V dc 1A 2.1mm Plug
<b>Operating Temperature</b>	10 to 40°C (50 to 104°F)
<b>Operating Humidity</b>	35% to 80% RH, Non-Condensing
<b>Storage Temperature</b>	-10 to 60°C (14 to 140°F)
<b>Storage Humidity</b>	20% to 80% RH, Non-Condensing

## Software Included

- Driver for Windows 3.1/3.11
- Driver for Windows 95
- TextBridge  
*OCR (Optical Character Recognition software) package that scans and converts pages of text ready to be used within a wordprocessor*
- Scanning Desktop  
*Desktop program to control scanning facilities*
- iPhoto Plus  
*Software package that controls the scan and allow image processing*

- iPhoto Plus 4  
*Same as iPhoto Plus above but suitable for Windows 95. This package has a more advanced interface and comes on a separate CD*
- Acrobat Reader 2.1  
*Used to view Portable Document Files (PDF)*

## Hardware Included

- External power supply
- Connecting lead (scanner to computer)
- Software
- Manuals