

LABFACILITY

TEMPERATURE TECHNOLOGY


INSTALLATION FITTINGS FOR TEMPERATURE PROBES

FLANGE PLATES

Labfacility flange plates enable the mounting of temperature probes with compression fittings. Available in stainless steel and brass, flange plates are particularly recommended for mounting probes in process ovens, kilns, heating and ventilating ducts, etc

Diameter 50mm
Female thread 1/8" BSP
Mounting holes 3 x 4mm dia. on 40mm PCD


ORDER CODES	
STAINLESS STEEL	CA-250
BRASS	CA-251

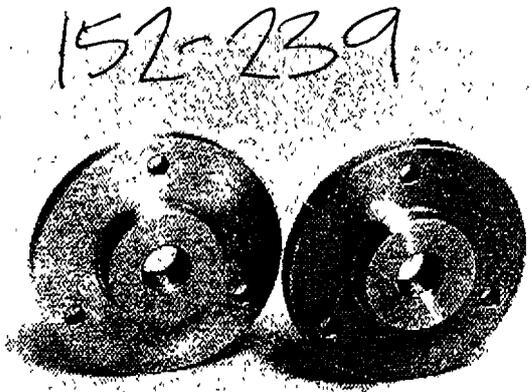

BAYONET FITTINGS AND ADAPTORS

Labfacility offers a range of bayonet fittings and associated adaptors for securing temperature sensors. When fitted, a bayonet fitting spring loads the sensor to keep it in permanent contact with the measured surface. Bayonet fittings are particularly suitable for mounting sensors in plastics extruders, injection moulding machines, etc.

Two types of bayonet fixing are available (compression or grub screw). Select the fitting to suit sensor diameter. Adaptors are available in two thread sizes and various lengths.

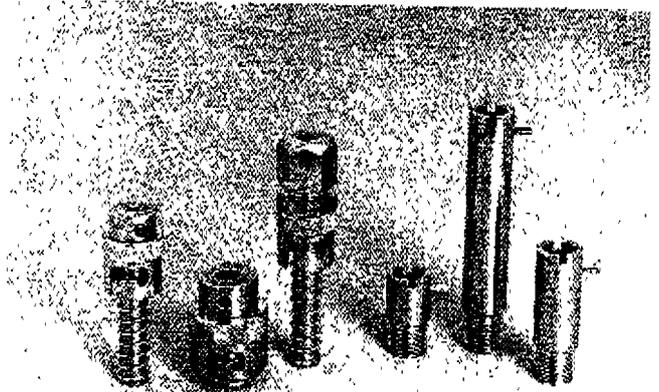

ORDER CODES - BAYONET FITTINGS

TYPE	FITTING	PROBE DIA. (mm)	ORDER CODE
Single slot cap	Compression	3.0	CA-300
Single slot cap	Compression	4.5	CA-301
Single slot cap	Grub screw	3.0	CA-302
Single slot cap	Grub screw	4.5	CA-303
Twin slot cap	Grub screw	6.0	CA-304

ORDER CODES - ADAPTORS

THREAD SIZE	OVERALL LENGTH (mm)	PINS	ORDER CODE
1/8" BSP	22	Single	CA-400
1/8" BSP	35	Single	CA-401
1/8" BSP	48	Single	CA-402
1/8" BSP	64	Single	CA-403
1/8" BSP	22	Double	CA-404
M10 x 1mm	35	Single	CA-405

Specifications may be subject to change

LABFACILITY LIMITED

Tel: 0181 943 5331 Fax: 0181 943 4351

HEAD OFFICE: LABFACILITY LTD, 99 Waldegrave Road, Teddington, Middlesex TW11 1BL, UK. Tel: 0181 943 5331 Telex: 8952151 Intemp G Fax: 0181 943 4351
NORTHERN OFFICE: LABFACILITY LTD, Unit 7 Abbey Way, North Anston Trading Estate, Dinnington, Sheffield S31 7LJ, UK. Tel: 01909 569446 Fax: 01909 550632

