


CUSTOMER	CPC
PRODUCT NO.	CS20546
REVISION NO.	LC088

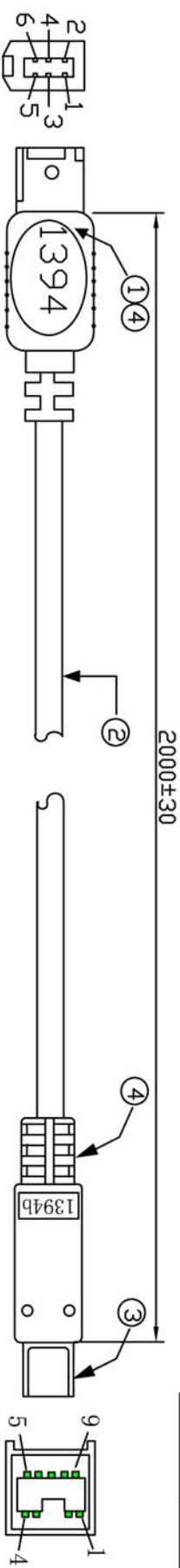

P1 1394 6P

P2 1394 9PM

Pin out:


P1	5	6	3	4	1	2	SHELL
	F1	F1	F2	F2		F1 F2	
P2	1	2	3	4	8	9	5 6
							SHELL

5				1	SET
4	45P PVC Transparent;			1	SET
3	1394b 9P M			1	SET
2	OD: 5.5 L=2000MM			1	PCS
1	1394 6P			1	SET

NOTE:

1. 100% OPEN, SHORT&MISWIRE TEST;
2. ALL MATERIALS MUST BE IN LINE WITH ROHS.

00	NEW	2011/01/27	GENERAL TOLERANCES (UNLESS SPECIFIED)	
REV	DESCRIPTION	DATE	LENGTH: X. ±1	
			.X±0.2	
			.XX±0.10	
			ANGLE: X°. ±1°	
			.X° ±0° 30'	
UNIT: mm	REV: 00			NAME
DRAWING	OVP	2011/01/27	S. P. NO.	HT-2047
CHECK			P. O. NO.	
APPROVE			SIZE	
			PAGE	1/1

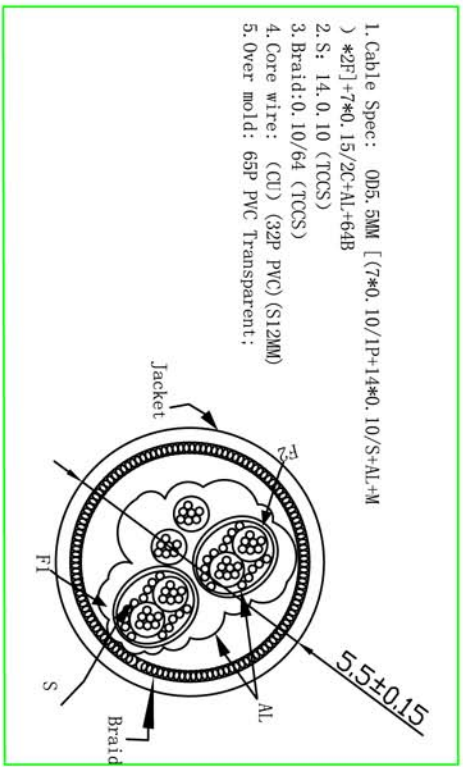

1. Cable Spec: 005.5MM [(7*0.10/1P+14*0.10/S+AL+M)*2P]+7*0.15/2C+AL+64B
2. S: 14.0.10 (TCCS)
3. Braid: 0.10/64 (TCCS)
4. Core wire: (CU) (32P PVC) (SI2MM)
5. Over mold: 65P PVC Transparent;