


CUSTOMER	CPC
PRODUCT NO.	CS20547
REVISION NO.	UC089

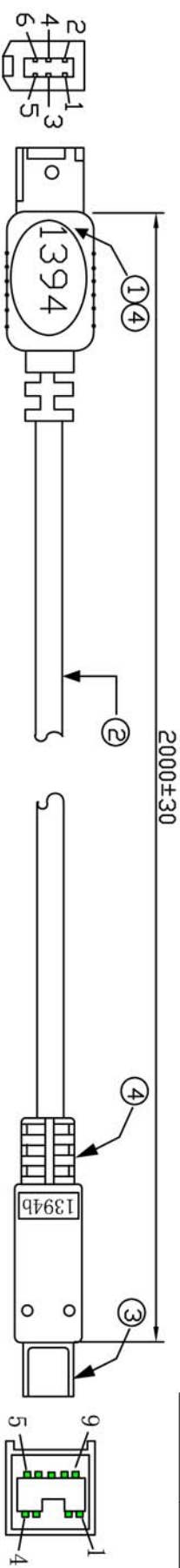

Pin out:


P1	1	2	9	3	4	5	6	8	SHELL
	F1	F1	F1	F2	F2	F2			
P2	3	4	5	1	2	9	6	8	SHELL

5		45P PVC Transparent;	1	SET
4		1394b 9P M	1	SET
3		OD: 5.5 L=2000MM	1	PCS
2		1394b 9P M	1	SET
1				

NOTE:

1. 100% OPEN, SHORT&MISWIRE TEST;
2. ALL MATERIALS MUST BE IN LINE WITH ROHS.

00	NEW	2011/01/27	GENERAL TOLERANCES (UNLESS SPECIFIED)		UNIT: mm		REV: 00	NAME		1394 9PM-9PM
REV	DESCRIPTION	DATE	LENGTH: X. ±1	ANGLE: X° ±1°	DRAWING	OVP	2011/01/27	S. P. NO.	HT-2048	DWG. NO.
			.X±0.2	.X° ±0° 30'	CHECK			P. O. NO.		PAGE
			.XX±0.10		APPROVE			SIZE		1/1

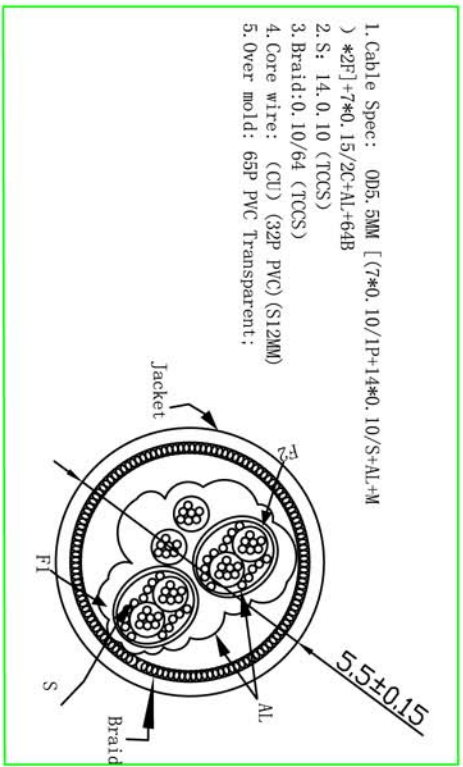

1. Cable Spec: 0D5.5MM [(7*0.10/1P+14*0.10/S+AL+M)*2P]+7*0.15/2C+AL+64B
2. S: 14.0.10 (TCCS)
3. Braid: 0.10/64 (TCCS)
4. Core wire: (CU) (32P PVC) (SI2MM)
5. Over mold: 65P PVC Transparent;