



PAH.N0.3GL.LC65GZ

MECHANICAL DETAILS

- Shell Style Model** PA* : Straight plug with cable collet
- Keying** 2 keys (beta=170; plug: female contacts, receptacle: male contacts)
- Housing Material** PSU (Polysulfone), gray
- Cable Fixing** 5.3 - 6.5 mm
- Variant 2** G : Gray collet nut for bend relief


	A	L	S1
Mm.	14	48	S9
In.	0.55	1.89	

PERFORMANCE DETAIL

- Insert** 1P.N03 : 3 High Voltage
- Insulator**
- Specifications**
- Note:** Increased creepage distance, pin 3 longer
- Contact Type:** Solder
- Max. Matings:** 2000
- Contact Dia.:** 0.9 mm (0.04in)
- Bucket Dia.:** 1.4 mm (0.055in)
- Max. Solid** 1 mm² (AWG 18)
- Max. Stranded** 1 mm² (AWG 18)
- R (max):** 4.5 mOhm
- Cable type:** |A|H07

OTHER CHARACTERISTICS

- Shell Style/Model** Libellé
- F ret (min):** 50 N
- F ret (max):** 150 N
- IP Rating** 50

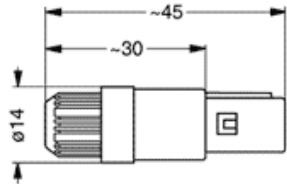

Available Download

[P_series_catalog.pdf](#)

Related links

- [Contact](#)
- [Quote Request](#)
- [Catalogs Downloads](#)
- [Catalogs Requests](#)
- [Sample Request](#)
- [3D drawings](#)