

rotronic

Datenblatt - Fiche technique - Data sheet




11.02.8310



**ROLINE USB 2.0 Kabel, Typ A ST – Micro B ST,
0,15 m**

**ROLINE Câble USB 2.0, USB A mâle – Micro USB B mâle,
0,15 m**

**ROLINE USB 2.0 Cable, USB Type A M – Micro USB B M,
0.15 m**

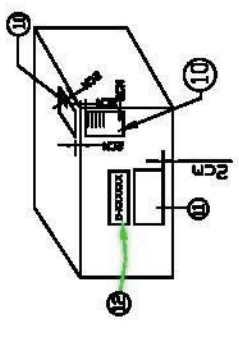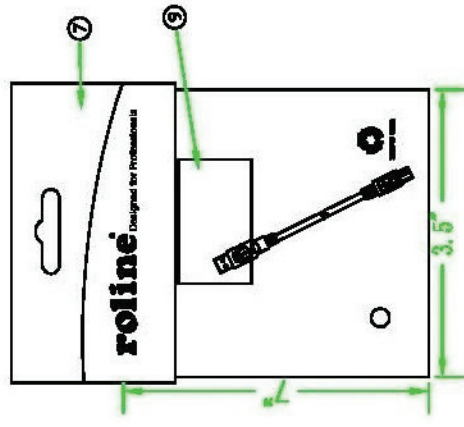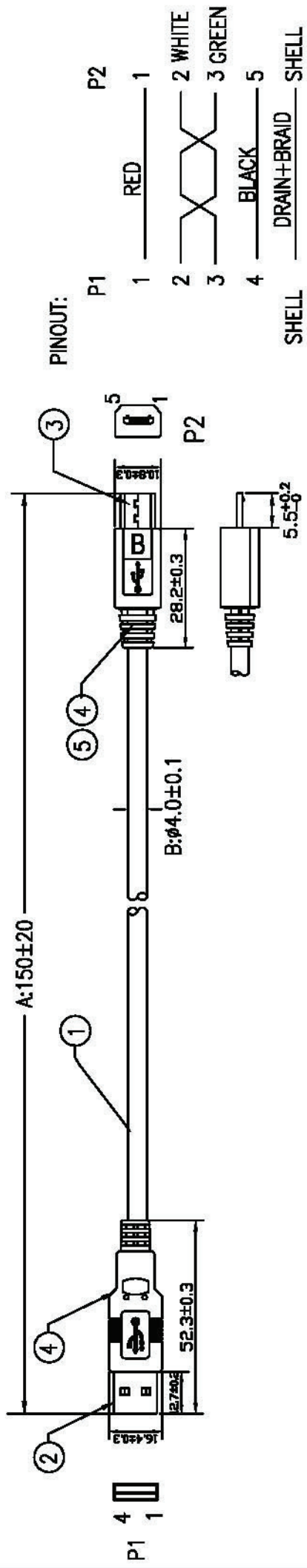

NOTE:

- 1) PRIMARY DIMENSION: A,B
- 2) P1 USB A Male, P2 USB Micro B male
- 3) ROHS & REACH COMPLIANT
- 4) 28AWG x 1 PR + 28 AWG x 2C, gold plated pin 30U", 15cm, black color
- 5) 1 PC/ PE BAG + ROLINE HEADER CARD

5	INNER JACKET:PE (RoHS)
4	OUTER JACKET PVC 45Pa BLACK(110T) (RoHS)
3	MicroUSB B PLUG BLACK TERMINAL PLATED GOLD 30U" SOLDER TYPE (RoHS)
2	USB A TYPE 4P MALE WHITE TERMINAL PLATED GOLD 30U" SOLDER TYPE (RoHS)
1	Micro USB2.0 UL2725(28#1P+AL)+28#2C+A+D+B(65%) OD:4.0mm BLACK(110T) 150MM (RoHS)

rotronic		ROLINE USB 2.0 CABLE, USB AM TO	
		USB MICRO BM, BLACK, 0.15M	
DIMENSIONS	TOLERANCE	CONF.	
0.00 TO 30.00mm	±0.10mm		
30.01 TO 80.00mm	±0.15mm	APPL.	
80.01 TO 180.00mm	±0.15mm		
180.01mm	±0.20mm		
MATERIAL			
FINISH			
DR.	999		
PART NO.	11.02.8310		
SCALE	1/1	UNIT	MM
SHEET		SIZE	A4
REV.			A