

rotronic

Datenblatt - Fiche technique - Data sheet


11.99.8819




VALUE USB 2.0 Kabel, Typ A-B, 1,8m

VALUE Câble USB 2.0 Type A-B, 1.8m

VALUE USB 2.0 Cable, Type A-B, 1.8 m

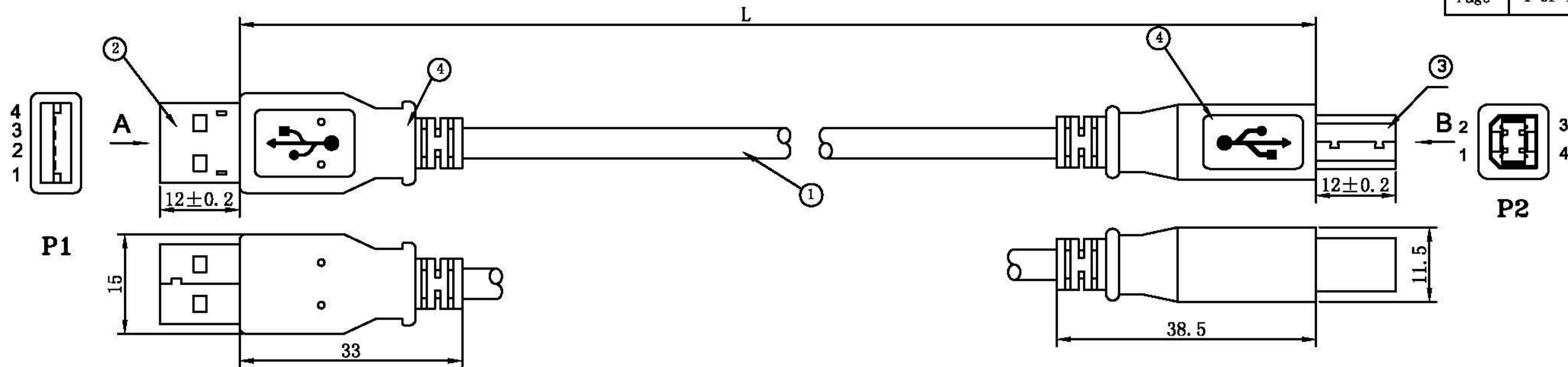

PIN OUT

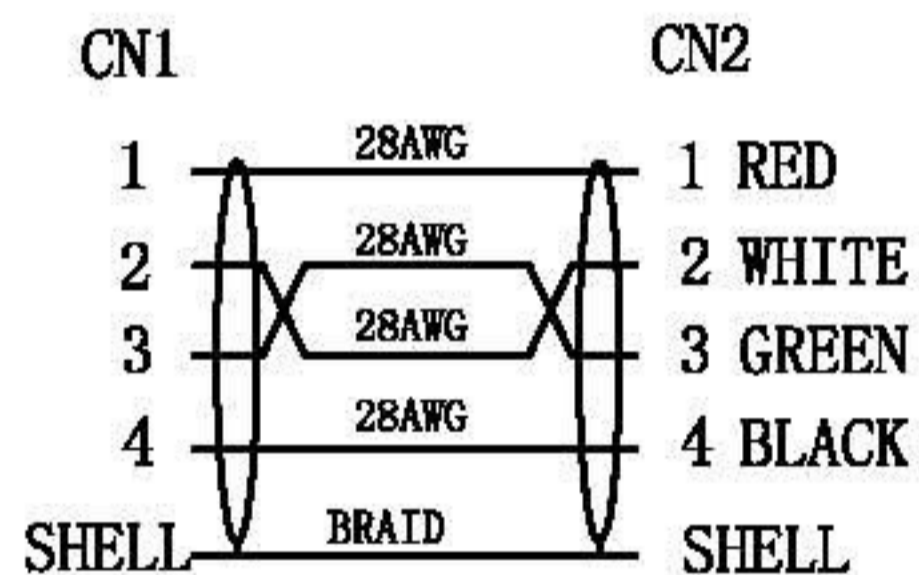

NOTE:

ITEM NO	LENGTH
11.99.8809	800mm
11.99.8819	1800mm
11.99.8831	3000mm
11.99.8841	4500mm

NOTE:

- Electrical test:
 - 100% open short & miss wire test;
 - Insulation resistance:DC 300V 10M Ω;
 - Contact resistance:3 Ω Max;
 - Dielectric strength:100V AC/Minute, 1mA.
- RoHS & REACH compliant
- PRINTING:USB 2.0 CABLE, 28AWG×1P+28AWG×2C
- Packing: 1PCS/PE BAG + LABEL 100PCS/CARTON

MATERIAL LIST:

④	OUTER MOLD	Shore 88A PVC(UL94V-2) Color: White	2	
③	USB B TYPE	USB B /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating	1	
②	USB A TYPE	USB A /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating	1	
①	CABLE	USB 2.0 28AWG(7/0.12BC*1P)+28AWG(7/0.12BC*2C)+AB B=0.12/3*16 AL-MG JACKET:PVC/WHITE OD: 4.0mm, Braid Coverage: 48%	1	

NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

Rotronic Co., Ltd.				
CUSTOMER	RT	REF.	ITEM NO.	See The Chart
PRODUCT NAME	VALUE USB 2.0 Cable, AM/BM		UNTT	MM
DRAWNBY	CHECKBY	APPOBY	DATE	
Elaine			2011-08-02	